


Ленточная ручка RatiopacPRO/-AIR

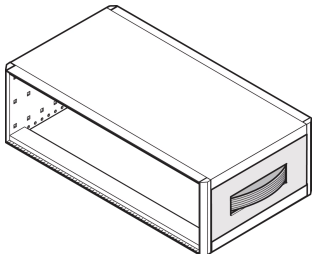

Скобяная ручка для RatiopacPRO/-AIR с допустимой статической нагрузкой 20 кг. Возможность модернизации без механической обработки на корпусе.

CERTIFICATIONS



FEATURES

Допустимая статическая нагрузка 20 кг

Возможность модернизации без механической обработки на боковой панели корпуса

SPECIFICATIONS

- Works With:** Coffrets
- Product Type:** Ручка
- Product Family:** RatiopacPRO; RatiopacPRO AIR

Table 1/1

Catalog Number	Rack Height	Глубина мм	Package Quantity	Handle Type	Quick Ship
24571-308	3U	315mm	1	Strap	No
24571-316	4U	435mm	1	Strap	No
24571-315	4U	375mm	1	Strap	No
24571-314	4U	315mm	1	Strap	No

Catalog Number	Rack Height	Глубина мм	Package Quantity	Handle Type	Quick Ship
24571-309	3U	375mm	1	Strap	No
24571-310	3U	435mm	1	Strap	No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE