


Задняя панель для серии RatiopacPRO/PropacPRO, с перфорацией, возможно дооснащение экранированием

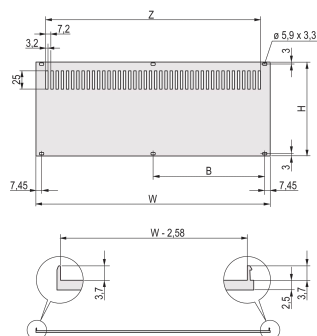

Перфорированная задняя панель, Al, 2,5 мм, без экранирования. Задняя сторона проводящая.

CERTIFICATIONS



FEATURES

Задняя панель, алюминий, 2,5 мм, лицевая поверхность: анодирование, тыльная поверхность: токопроводящая; неэкранированная

Позволяет выполнять монтаж на горизонтальных рейках

SPECIFICATIONS

Material:	Алюминий
Finish:	Anodized; Passivated
Works With:	Coffrets
Product Family:	RatiopacPRO; RatiopacPRO AIR
Type:	Rear Panel
Product Type:	Side Panel

Table 1/1

Catalog Number	Rack Height	Rack Width	Package Quantity	Высота мм	Ширина мм	Quick Ship
20848-680	2U	42HP	1	83.5mm	213mm	No
20848-681	2U	63HP	1	83.5mm	319.7mm	No
20848-633	3U	28HP	1	123.4mm	141.9mm	No
20848-634	3U	42HP	1	123.4mm	213mm	No
20848-635	3U	63HP	1	123.4mm	319.7mm	No
20848-636	3U	84HP	1	123.4mm	426.4mm	No
20848-657	4U	42HP	1	168.9mm	213mm	No
20848-658	4U	63HP	1	168.9mm	319.7mm	No
20848-659	4U	84HP	1	168.9mm	426.4mm	No
20848-643	6U	84HP	1	256mm	426.4mm	No
20848-640	6U	28HP	1	256mm	141.9mm	No
20848-641	6U	42HP	1	256mm	213mm	No
20848-642	6U	63HP	1	256mm	319.7mm	No
20848-656	4U	28HP	1	168.9mm	141.9mm	No
20848-679	2U	28HP	1	83.5mm	141.9mm	No
20848-682	2U	84HP	1	83.5mm	426.4mm	No
20848-744	5U	28HP	1	220mm	141.9mm	No
20848-745	5U	42HP	1	220mm	213mm	No

CatalogNumber	Rack Height	Rack Width	Package Quantity	Высота мм	Ширина мм	Quick Ship
20848-746	5U	63HP	1	220mm	319.7mm	No
20848-747	5U	84HP	1	220mm	426.4mm	No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE