


Пластиковая втулка для M2.5

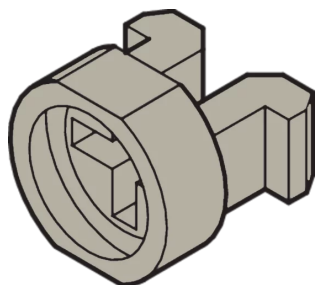

Втулка служит направляющей для винта с проточкой при креплении передней панели.

CERTIFICATIONS



FEATURES

Втулка служит направляющей для винта с проточкой при креплении передней панели

Втулка вставляется в удлиненное отверстие в передней панели

SPECIFICATIONS

Works With: Передние панели

Product Type: Sleeve

Table 1/2

Catalog Number	Material	Finish	Color	Package Quantity	Color Code	Глубина мм (D)
21100-886	Brass	Organic Top Coat		100		4.4mm
21100-662	Нержавеющая сталь			100		4.4mm
21100-660	Brass	Nickel Plated		100		4.4mm


CatalogNumber	Material	Finish	Color	Package Quantity	Color Code	Глубина мм(D)
21100-591	Polyamide 6		Jet Black	100	RAL 9005	6.9mm
21100-464	Polyamide 6		Pebble Grey	100	RAL 7032	6.9mm
21100-659	Brass	Nickel Plated		10		
21100-661	Нержавеющая сталь			10		
21100-885	Brass			10		

Table 2/2				
Catalog Number	Высота мм (H)	Ширина мм (W)	Flammability Rating	Quick Ship
21100-886	6mm	8mm		No
21100-662	6mm	8mm		No
21100-660	6mm	8mm		No
21100-591	6mm	6.8mm	UL® 94V-2	No
21100-464	6mm	6.8mm	UL® 94V-2	No
21100-659				No
21100-661				No
21100-885				No

ADDITIONAL PRODUCT DETAILS

Металлические втулки на передних панелях неполной ширины должны запрессованы.

Все втулки можно использовать для передних панелей с шириной стойки больше 2 HP (Horizontal Pitch).

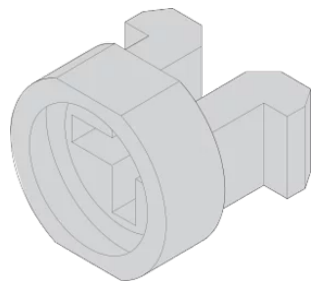

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE