


панель электропитания, UTE

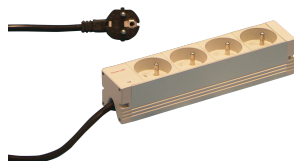

Компактная модульная конструкция панели электропитания с множеством функциональных элементов. Распределительный блок питания с алюминиевым шасси размером 1 U x 1 U легко интегрируется в шкаф с розетками UTE.

CERTIFICATIONS



FEATURES

230 В., 16 А

В соответствии с NFC 61-303

Панель электропитания с розетками UTE

Монтажная высота 1 U

Возможен горизонтальный и вертикальный монтаж

Сетевой кабель 2 м, штекер SCHUKO/UTE

При установке панель электропитания можно развернуть в любую сторону (с шагом 90°)

SPECIFICATIONS

Material:	Алюминий; Polyamide
Color:	Серый
Product Type:	Панели электропитания

Table 1/2

Catalog Number	Socket Type	Socket Quantity	Switched Outlets	Voltage AC	Function	Package Quantity
----------------	-------------	-----------------	------------------	------------	----------	------------------

60110-220	UTE	4	Нет	230V		1
60110-221	UTE	9	Нет	230V		1
60110-222	UTE	12	Нет	230V		1
60110-223	UTE	15	Нет	230V		1
60110-224	UTE	19	Нет	230V		1
60110-225	UTE	8	Да	230V		1
60110-226	UTE	12	Да	230V		1
60110-227	UTE	8	Нет	230V	Transient Protection	1
60110-228	UTE	6	Нет	230V	Overcurrent Protection	1
60110-229	UTE	7	Нет	230V	Mains Suppression Filter	1
60110-230	UTE	6	Нет	230V	Fault Current Protection	1
60110-231	UTE	6	Нет	230V	Fault Current Protection, Overcurrent Protection	1
60110-267	UTE	6	Нет	230V	Transient Protection, Mains Suppression Filter	1

Table 2/2

Catalog Number	Глубина мм	Finish	Длина мм	Quick Ship
60110-220	44mm	Anodized	210mm	No
60110-221	44mm	Anodized	438.5mm	No
60110-222	44mm	Anodized	947.5mm	No

Catalog Number	Глубина мм	Finish	Длина мм	Quick Ship
60110-223	44mm	Anodized	1202mm	No
60110-224	44mm	Anodized	1753mm	No
60110-225	44mm	Anodized	438.5mm	No
60110-226	44mm	Anodized	947.5mm	No
60110-227	44mm	Anodized	438.5mm	No
60110-228	75mm	Anodized	438.5mm	No
60110-229	44mm	Anodized	438.5mm	No
60110-230	88mm	Anodized	438.5mm	No
60110-231	88mm	Anodized	438.5mm	No
60110-267	44mm	Anodized	438.5mm	No

ADDITIONAL PRODUCT DETAILS

Кронштейн для вертикального монтажа заказывается отдельно.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE