


19-дюймовая полка Varistar, стационарная, 75 кг

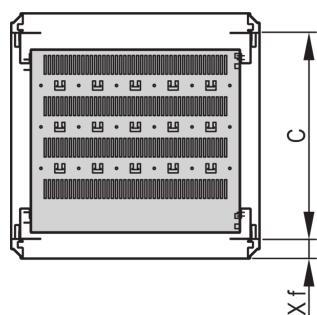

19-дюймовая полка Varistar, стационарная, 75 кг.

CERTIFICATIONS



FEATURES

Допустимая статическая нагрузка 75 кг

Сталь, 1,5 мм

С заземлением

ширина 495 мм

Для установки на четырех 19-дюймовых панелях / монтажных профилях

SPECIFICATIONS

Product Type: Полка с креплением на каркасе

Material: Сталь

Table 1/2

Catalog Number	Ширина мм	Глубина мм	Package Quantity	Color	Color Code	Finish
21130-302	495mm		1	Black Grey	RAL 7021	Powder Coated

CatalogNumber	Ширина мм	Глубина мм	Package Quantity	Color	Color Code	Finish
21130-303	495mm		1	Black Grey	RAL 7021	Powder Coated
21130-304	495mm	800mm	1	Black Grey	RAL 7021	Powder Coated
21130-305	495mm	800mm	1	Black Grey	RAL 7021	Powder Coated
21130-309	495mm		1	Black Grey	RAL 7021	Powder Coated
22130-302	495mm		1	Light Grey	RAL 7035	Powder Coated
22130-303	495mm		1	Light Grey	RAL 7035	Powder Coated
22130-304	495mm	800mm	1	Light Grey	RAL 7035	Powder Coated
22130-305	495mm	800mm	1	Light Grey	RAL 7035	Powder Coated
22130-309	495mm		1	Light Grey	RAL 7035	Powder Coated

Table 2/2

Catalog Number	Высота мм	Длина мм	Type	Quick Ship
21130-302	400mm	342mm	Recessed Depth	No
21130-303	500mm	442mm	Full Depth	No
21130-304	600mm	642mm	Recessed Depth	No
21130-305	700mm	642mm	Full Depth	No
21130-309	740mm	682mm	Full Depth	No
22130-302	400mm	342mm	Recessed Depth	No
22130-303	500mm	442mm	Full Depth	No
22130-304	600mm	642mm	Recessed Depth	No

Catalog Number	Высота мм	Длина мм	Type	Quick Ship
22130-305	700mm	642mm	Full Depth	No
22130-309	740mm	682mm	Full Depth	No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE