


Varistar CP Double Steel Door, Perforated With 3-Point Electronic Locking

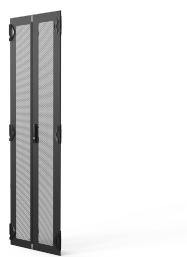

Perforated Varistar CP steel double door with 3-point locking and 2 door hinges for applications with IP 20 protection.

FEATURES

Double perforated steel door with 3-point locking for IP 20 protection class

Lever handle with push button, key

Opening angle 180°

Standard fitting, lock on right-hand door

Can be retrofitted with DIN profile half cylinder

SPECIFICATIONS

Locking Type: 3-Point Locking, Electronic

Product Type: Cabinet Door

Protection Rating: IP20

Material: Сталь

Table 1/2

Catalog Number	Rack Height	Высота мм	Ширина мм	Package Quantity	Color	Color Code
21630-822	52U	2450mm	600mm	1	Black Grey	RAL 7021
21630-820	42U	2000mm	600mm	1	Black Grey	RAL 7021
21630-825	52U	2450mm	800mm	1	Black Grey	RAL 7021

CatalogNumber	Rack Height	Высота мм	Ширина мм	Package Quantity	Color	Color Code
21630-824	47U	2200mm	800mm	1	Black Grey	RAL 7021
21630-821	47U	2200mm	600mm	1	Black Grey	RAL 7021
21630-823	42U	2000mm	800mm	1	Black Grey	RAL 7021

Table 2/2					
Catalog Number	Complies With	Finish	Type	Works With	Quick Ship
21630-822	IEC 61587-1	Powder Coated	Steel Double Door, Perforated	Varistar CP	No
21630-820	IEC 61587-1	Powder Coated	Steel Double Door, Perforated	Varistar CP	No
21630-825	IEC 61587-1	Powder Coated	Steel Double Door, Perforated	Varistar CP	No
21630-824	IEC 61587-1	Powder Coated	Steel Double Door, Perforated	Varistar CP	No
21630-821	IEC 61587-1	Powder Coated	Steel Double Door, Perforated	Varistar CP	No
21630-823	IEC 61587-1	Powder Coated	Steel Double Door, Perforated	Varistar CP	No

ADDITIONAL PRODUCT DETAILS

Please order DIN profile half cylinder for lever handle separately.

Please purchase the grounding kit separately.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE