


Направляющий рельс Varistar

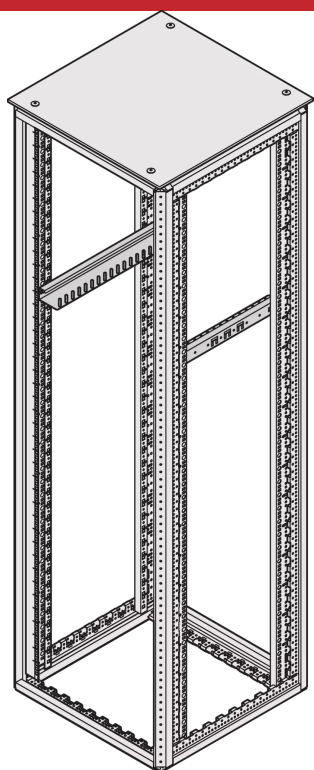

Монтируется на четырех 19-дюймовых монтажных профилях грузоподъемностью 25/100 кг.

CERTIFICATIONS



FEATURES

Установка на 19-дюймовых монтажных профилях

Широкая поверхность опоры (48 мм)

Высота установки в шкафу определяется шагом 1 U (навеска и крепление на винтах)

SPECIFICATIONS

Product Type: Slide Rail

Material: Сталь

Table 1/2

Catalog Number	Static Load	Package Quantity	Finish	Высота мм	Длина мм	Works With
23130-099		2	Aluminum-Zinc Plated			Varistar CP
23130-116	100kg	2	Aluminum-Zinc Plated	200mm	156mm	Varistar CP
23130-096	25kg	2	Aluminum-Zinc Plated	500mm	456mm	Varistar CP
23130-097	25kg	2	Aluminum-Zinc Plated	700mm	656mm	Varistar CP
23130-098	25kg	2	Aluminum-Zinc Plated	740mm	699mm	Varistar CP
23130-118	100kg	2	Aluminum-Zinc Plated	500mm	458mm	Varistar CP
23130-119	100kg	2	Aluminum-Zinc Plated	700mm	658mm	Varistar CP
23130-120	100kg	2	Aluminum-Zinc Plated	740mm	699mm	Varistar CP
23130-126		10	Aluminum-Zinc Plated			Varistar CP
23130-101	25kg	10	Aluminum-Zinc Plated	500mm	456mm	Varistar CP
23130-102	25kg	10	Aluminum-Zinc Plated	700mm	656mm	Varistar CP
23130-103	25kg	10	Aluminum-Zinc Plated	740mm	699mm	Varistar CP
23130-123	100kg	10	Aluminum-Zinc Plated	500mm	458mm	Varistar CP
23130-124	100kg	10	Aluminum-Zinc Plated	700mm	658mm	Varistar CP
23130-125	100kg	10	Aluminum-Zinc Plated	740mm	699mm	Varistar CP

Table 2/2

Catalog Number	Package Unit	Certifications	Quick Ship
23130-099	Pair		No

Catalog Number	Package Unit	Certifications	Quick Ship
23130-116		RoHS	No
23130-096	Pair	RoHS	No
23130-097	Pair	RoHS	No
23130-098	Pair	RoHS	No
23130-118		RoHS	No
23130-119		RoHS	No
23130-120		RoHS	No
23130-126		RoHS	No
23130-101		RoHS	No
23130-102		RoHS	No
23130-103		RoHS	No
23130-123		RoHS	No
23130-124		RoHS	No
23130-125		RoHS	No

ADDITIONAL PRODUCT DETAILS

При монтаже в шкафу 19-дюймовые панели / монтажные профили должны быть установлены спереди и сзади.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE