


Объединительная плата VPX

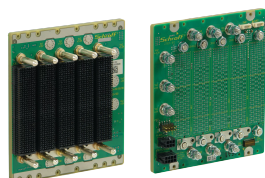

Объединительная плата nVent SCHROFF VPX обеспечивает превосходную целостность сигнала для самых высоких скоростей передачи данных.

CERTIFICATIONS



FEATURES

В соответствии с: Базовый стандарт VITA 46.0 VPX; VITA 46.3 Serial RapidIO на VPX; VITA 46.4 PCI Express на коммутационном разъеме VPX; VITA 46.7 Ethernet на коммутационном разъеме VPX; Управление системой VITA 46.11 для VPX

DIP-переключатель для настройки системного слота

Разъемы JTAG

Блокируемые вспомогательные разъемы и сенсорные разъемы

Резьбовые клеммы питания M4, макс. 22 А на слот для каждого значения напряжения

SPECIFICATIONS

Table 1/2

Catalog Number	Product Type	Number of Slots	Rack Height	Backplane Type	Slot Width	Connector Type
23001-812	Объединительная плата	5	3U	VPX Full-mesh	4HP	MultiGig
23001-813	Объединительная плата	5	3U	VPX Full-mesh	4HP	MultiGig

CatalogNumber	Product Type	Number ofSlots	Rack Height	BackplaneType	Slot Width	ConnectorType
23001-814	Объединительная плата	7	3U	VPX, VITA 65	5HP	MultiGig
23001-815	Объединительная плата	7	3U	VPX, VITA 65	5HP	MultiGig
23001-816	Объединительная плата	10	6U	VPX, VITA 65	5HP	MultiGig
23001-834	Объединительная плата	9	3U	VPX, VITA 65	5HP	MultiGig

Table 2/2

Catalog Number	Power Connector Type	Utility Connector Type	Ширина мм	Package Quantity	Certifications	Quick Ship
23001-812	Powerstuds M4	Microfit, 8-pin	120.67mm	1	VITA, RoHS	No
23001-813	Powerstuds M4	Microfit, 8-pin	120.67mm	1	RoHS, VITA	No
23001-814	Powerstuds M4	Microfit, 8-pin	186.46mm	1	VITA, RoHS	No
23001-815	Powerstuds M4	Microfit, 8-pin	186.46mm	1	RoHS, VITA	No
23001-816	Powerstuds M4	Microfit, 8-pin	262.55mm	1	VITA, RoHS	No
23001-834	Powerstuds M4	Microfit, 8-pin	253mm	1	VITA	No

ADDITIONAL PRODUCT DETAILS

Другие варианты объединительных плат VPX и специальных конструкций объединительной платы VPX доступны по запросу.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE