

4G16 Twist Clip with Stud



CERTIFICATIONS



FEATURES

Supports electrical fixtures from acoustical T-grid

No tools required for installation

Fast, easy and secure twist-on installation

Nut sold separately

SPECIFICATIONS


Table 1/2

Catalog Number	Article Number	Material	Finish	Color	Flange Thickness (FT)	T-Grid Size
4G16M16	171900	Spring Сталь, Сталь	nVent CADDY Armour	Gray	1.5 mm	24mm
4G16M25	176880	Spring Сталь, Сталь	nVent CADDY Armour	Gray	1.5 mm	24mm
4G16M11	178600	Spring Сталь, Сталь	nVent CADDY Armour	Gray	1.5 mm	24mm

CatalogNumber	Article Number	Material	Finish	Color	Flange Thickness (FT)	T-Grid Size
4G16M11WH	178620	Spring Сталь, Сталь	Painted	White	1.5 mm	24mm
4G16M7	178590	Spring Сталь, Сталь	nVent CADDY Armour	Gray	1.5 mm	24mm
4G16M16WH	576940	Spring Сталь, Сталь	Painted	White	1.5 mm	24mm

Table 2/2				
Catalog Number	Article Number	Screw Diameter (Sc)	Screw Length (L)	Static Load
4G16M16	171900	6	16mm	220N
4G16M25	176880	6	25mm	220N
4G16M11	178600	6	11mm	220N
4G16M11WH	178620	6	11mm	220N
4G16M7	178590	6	7mm	220N
4G16M16WH	576940	6	16mm	220N

DIAGRAMS

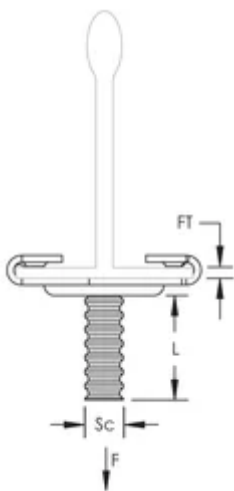

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper

installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

