

APX External Vertical Wall Bracket



FEATURES

Saddle support for C-Profiles and strut

Complete with fixings

SPECIFICATIONS

Table 1/2


Catalog Number	Article Number	Material	Finish	Channel Type	Strut Type	Height (H)
APXE23EG	584710	Сталь	Electrogalvanized	E2L, E2, E3		114 mm
APXE01EG	584715	Сталь	Electrogalvanized	E0L, E0, E1		114 mm
APXE4STRUTEG	584725	Сталь	Electrogalvanized	E4	A (41 x 41 mm), C (21 x 41 mm)	144 mm
APXSTRUTS6	584820	Stainless Steel 316 (EN 1.4401)			A (41 x 41 mm), C (21 x 41 mm)	144 mm

Table 2/2

Catalog Number	Article Number	Width (W)	Thickness (T)	A	B	C
APXE23EG	584710	50 mm	5 mm	36 mm	12 mm	19 mm

CatalogNumber	Article Number	Width (W)	Thickness (T)	A	B	C
APXE01EG	584715	50 mm	5 mm	31 mm	12 mm	19 mm
APXE4STRUTEG	584725	70 mm	5 mm	43 mm	12 mm	19 mm
APXSTRUTS6	584820	70 mm	6 mm	43 mm	12 mm	19 mm

DIAGRAMS

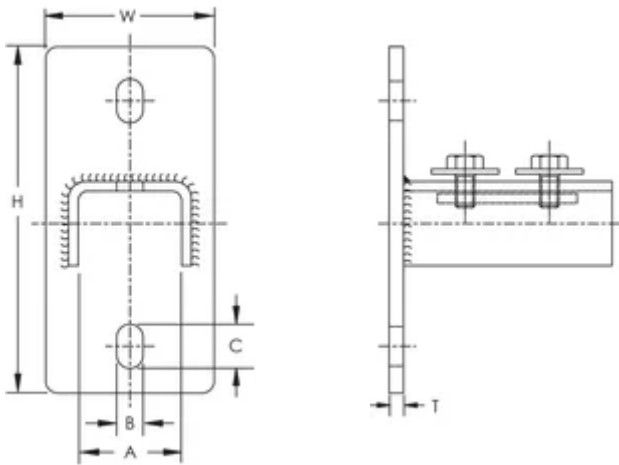

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

