

Branch Line Restraint Pipe Attachment



CERTIFICATIONS



FEATURES

Accepts 3/8" or 1/2" (M10 or M12) threaded rod

Quick grip clamp simplifies measuring and cutting of threaded rod

Eliminates need to cut threaded rod to exact dimensions

Works with rough-cut threaded rod and eliminates pipe-side deburring

Can be installed with threaded rod above or below the service pipe

Shear-off head helps ensure correct torque and simplifies inspection

SPECIFICATIONS

Finish: Electrogalvanized

Material: Сталь

Table 1/2


Catalog Number	Article Number	NB/DN	Outer Diameter (OD)	Rod Size (RS)	Height (H)	Длина мм (L)
CSBBRP0200E G	404480	50	60.3 mm	10, 12	100.3 mm	68.3mm

CatalogNumber	Article Number	NB/DN	Outer Diameter (OD)	Rod Size (RS)	Height (H)	Длина мм (L)
CSBBRP0125EG	404478	32	42.2 mm	10, 12	82.6 mm	50mm
CSBBRP0100EG	404477	25	33.4 mm	10, 12	73.7 mm	41.4mm
CSBBRP0150EG	404479	40	48.3 mm	10, 12	88.9 mm	56.1mm

Table 2/2

Catalog Number	Article Number	Width (W)
CSBBRP0200EG	404480	22.2 mm
CSBBRP0125EG	404478	22.2 mm
CSBBRP0100EG	404477	22.2 mm
CSBBRP0150EG	404479	22.2 mm

DIAGRAMS

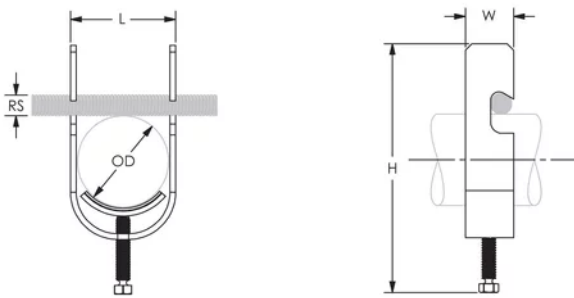

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

