

CHK Chain



CERTIFICATIONS



FEATURES

Versatile non-welded double loop chain

Conforms to DIN 5686

SPECIFICATIONS

Finish: Electrogalvanized


Material: Сталь

Table 1/1

Catalog Number	Article Number	Длина мм (L)	A	B	D	Static Load
CHK22K	385860	30m	28 mm	9 mm	2 mm	400N
CHK25K	385870	30m	31 mm	10 mm	2.2 mm	500N
CHK27K	385880	30m	35 mm	11 mm	2.5 mm	700N

CatalogNumber	Article Number	Длина мм (L)	A	B	D	Static Load
CHK30K	385890	30m	39 mm	12.5 mm	2.8 mm	900N
CHK32K	385900	25m	41 mm	14 mm	3.1 mm	1200N

DIAGRAMS

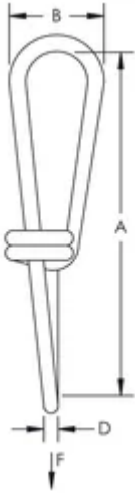

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

