

nVent CADDY Single-Arm Cable Pressure Clip



The nVent CADDY Single-Arm Cable Pressure Clip is a sustainable, ready-to-install metal clip allowing for easy cable installation with one hand. This solution securely supports small-sized cable bundles in crowded spaces—such as flush to ceilings, above suspended ceilings. The Single-Arm Pressure Clip’s unique design creates an option to combine two single-arm clips within seconds—ultimately doubling the cable capacity per a single fixing point, reducing the number of required stock parts, and saving contractors time on the job. Featuring a low-profile design, this cable pressure clip is a more durable alternative to commonly used plastic solutions and offers an ideal solution for electrical and datacom applications.

FEATURES

Gangable/Two-in-one solution; two nVent CADDY Single-Arm Cable Pressure Clips can be combined by hand to instantly double the cable capacity per single fixing point

Compatible with direct fastening and traditional anchoring

Reusable in case of nail misfire

More robust and durable than plastic pressure clips

Rounded edges help prevent cable damage

Cables are neatly installed, providing a consistent and professional appearance

Low-profile design allows for installation in tight spaces

Made of 100% recyclable materials

SPECIFICATIONS

Finish: Pregalvanized

Material: Сталь

Table 1/2

Catalog Number	Article Number	Hole Size (HS)	Длина мм (L)	Высота мм (H)	Ширина мм (W)	Diameter 1 (Ø1)
OAB8DF	182068	4.8 mm	115mm	15mm	30mm	4 - 10 mm


CatalogNumber	Article Number	Hole Size (HS)	Длина мм (L)	Высота мм (H)	Ширина мм(W)	Diameter 1(Ø1)
OAB8	182067	7.5 mm	115mm	15mm	30mm	4 - 10 mm

Table 2/2			
Catalog Number	Article Number	Diameter 2 (Ø2)	Cable Capacity
OAB8DF	182068	5 - 11 mm	8
OAB8	182067	5 - 11 mm	8

ADDITIONAL PRODUCT DETAILS

*Cable capacity based on a 10mm diameter cable

DIAGRAMS

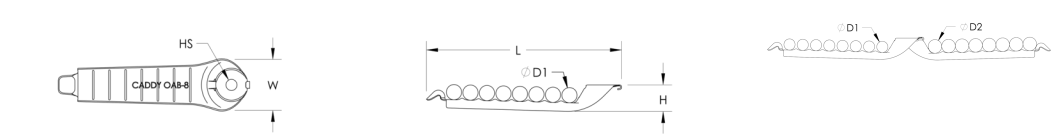

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
 Option 1 – Customer Care
 Option 2 – Technical Support

Europe

Netherlands:
 +31 800-0200135
 France:
 +33 800 901 793

Europe

Germany:
 800 1890272
 Other Countries:
 +31 13 5835404

APAC

Shanghai:
 + 86 21 2412 1618/19
 Sydney:
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

