

nVent CADDY Speed Link SLK with Wedge Anchor



FEATURES

Complete system includes wire, locking device and wedge anchor from fischerwerke GmbH &Co. KG

Quickly and easily attaches into cracked and non-cracked concrete

No special tools required

ETA 06/0175 approval available from fischerwerke GmbH &Co. KG

SPECIFICATIONS

Static Load Safety Factor:	5:1
Drill Bit Diameter:	6mm
Drill Hole Depth:	31mm
Embedment Depth:	25 mm Min
Finish:	Electrogalvanized
Material:	Сталь;Polypropylene;Zinc Alloy


Table 1/2

Catalog Number	Article Number	Wire Rope Diameter	Wire Rope Length	Длина мм (L)	Height (H)	Width (W)
SLK2L3WA6	196735	2 mm	3m	54mm	55 mm	19 mm
SLK15L3WA6	196672	1.5 mm	3m	54mm	55 mm	19 mm

CatalogNumber	Article Number	Wire Rope Diameter	Wire Rope Length	Длина мм (L)	Height (H)	Width (W)
SLK2L2WA6	196734	2 mm	2m	54mm	55 mm	19 mm
SLK15L2WA6	196671	1.5 mm	2m	54mm	55 mm	19 mm

Table 2/2				
Catalog Number	Article Number	Thickness (T)	Angle (a)	Static Load
SLK2L3WA6	196735	12.5 mm	90 ° Max	300N
SLK15L3WA6	196672	12.5 mm	90 ° Max	195N
SLK2L2WA6	196734	12.5 mm	90 ° Max	300N
SLK15L2WA6	196671	12.5 mm	90 ° Max	195N

DIAGRAMS

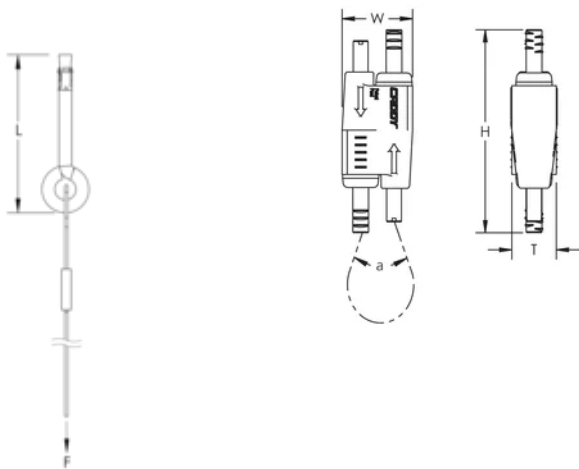

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

