

nVent CADDY Superfix 243 M8/M10



CERTIFICATIONS



FEATURES

Includes easy closing mechanism

Combo head bolt works with slotted, hex, or Phillips drivers

Category II noise reduction according to DIN EN ISO 3822-1

Compliant for sound insulation design according to DIN 4109

Reaction-to-fire classification is "E" in compliance with DIN EN 13501-1

SPECIFICATIONS

Color: Черный
Finish: Electrogalvanized
Temperature: -50 to 110 °C

Table 1/2

Catalog Number	Article Number	Material	Outer Diameter (OD)	NB/DN	Rod Size (RS)	Width (W)
SXD014	400063	Сталь, EPDM-SBR Rubber	12 - 16 mm	8	M8, M10	20 mm

CatalogNumber	Article Number	Material	Outer Diameter (OD)	NB/DN	Rod Size (RS)	Width (W)
SXD019	400064	Сталь, EPDM-SBR Rubber	15 - 19 mm	10	M8, M10	20 mm
SXD023	400065	Сталь, EPDM-SBR Rubber	20 - 23 mm	15	M8, M10	20 mm
SXD028	400066	Сталь, EPDM-SBR Rubber	26 - 30 mm	20	M8, M10	20 mm
SXD035	400067	Сталь, EPDM-SBR Rubber	31 - 36 mm	25	M8, M10	20 mm
SXD043	400068	Сталь, EPDM-SBR Rubber	40 - 43 mm	32	M8, M10	20 mm
SXD052	400070	Сталь, EPDM-SBR Rubber	48 - 53 mm	40	M8, M10	20 mm
SXD058	589350	Сталь, EPDM-SBR Rubber	50 - 55 mm		M8, M10	20 mm
SXD061	400071	Сталь, EPDM-SBR Rubber	60 - 64 mm	50	M8, M10	20 mm
SXD080	400074	Сталь, EPDM-SBR Rubber	74 - 80 mm	65	M8, M10	20 mm
SXD091	400075	Сталь, EPDM-SBR Rubber	87 - 92 mm	80	M8, M10	20 mm
SXD114	400077	Сталь, EPDM-SBR Rubber	108 - 114 mm	100	M8, M10	23 mm

Table 2/2


Catalog Number	Article Number	Thickness (T)	Screw Diameter (Sc)	Screw Length (L)	Static Load
SXD014	400063	1.2 mm	5	25mm	1000N
SXD019	400064	1.2 mm	5	25mm	1000N
SXD023	400065	1.2 mm	5	25mm	1000N
SXD028	400066	1.2 mm	5	25mm	1000N
SXD035	400067	1.2 mm	5	25mm	1000N

Catalog Number	Article Number	Thickness (T)	Screw Diameter (Sc)	Screw Length (L)	Static Load
SXD043	400068	1.2 mm	5	25mm	1000N
SXD052	400070	1.2 mm	5	25mm	1300N
SXD058	589350	1.2 mm	5	30mm	1300N
SXD061	400071	1.2 mm	5	30mm	1300N
SXD080	400074	2 mm	6	35mm	1300N
SXD091	400075	2 mm	6	35mm	1300N
SXD114	400077	2 mm	6	35mm	2200N

ADDITIONAL PRODUCT DETAILS

Lining is EPDM rubber.

DIAGRAMS

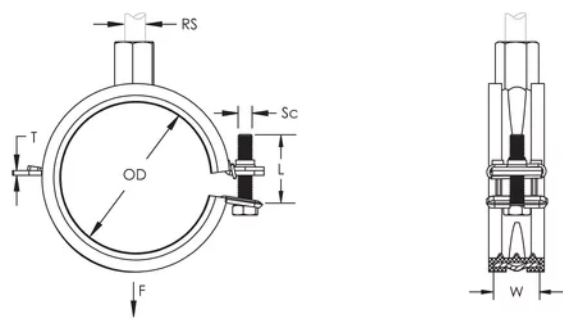

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

