


PEMSA Wire Basket Tray Cable Outlet

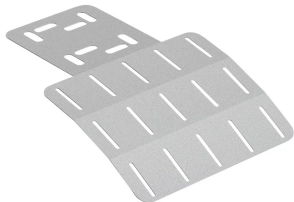

CERTIFICATIONS



FEATURES

Easy to install

Allows for easy exit angle adjustment (from 0 to 90 degrees)

SPECIFICATIONS

Material: Сталь

Table 1/2


Catalog Number	Article Number	Color	Finish	Длина мм (L)	Width 1 (W1)	Width 2 (W2)
WBTCBLOUTBA	820801	Черный		216mm	85 mm	150 mm
WBTCBLOUT	820800		Pregalvanized	216mm	85 mm	150 mm

Table 2/2

Catalog Number	Article Number	Thickness (T)	Hole Size 1 (HS1)	Hole Size 2 (HS2)	Certifications
----------------	----------------	---------------	-------------------	-------------------	----------------

WBTCBLOUTBA	820801	1.5 mm	7 - 20 mm	3 - 30 mm	
WBTCBLOUT	820800	1.5 mm	7 - 20 mm	3 - 30 mm	CE, CADDY EU WBT CBL

DIAGRAMS

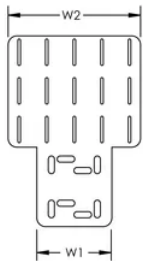

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

