

Quick Strut Nut



FEATURES

Provides fast universal attachment of threaded rod and hardware to standard strut profiles

Pre-assembled slide nut ready to use out of the box

Spring retains assembly in place until hardware is tightened

SPECIFICATIONS

Finish: Electrogalvanized

Material: Сталь

Table 1/2

Catalog Number	Article Number	Rod Size (RS)	A	B	C	Torque (TQ)
QSNM12EG	592930	12	8 mm	4 mm	41 mm	
QSNM8EG	592910	8	6 mm	4 mm	41 mm	28 N·m
QSNM10EG	592920	10	8 mm	4 mm	41 mm	55 N·m
QSNM6EG	592900	6	6 mm	4 mm	41 mm	

Table 2/2


Catalog Number	Article Number	Static Load 1 (F1)	Static Load 2 (F2)	Static Load 3 (F3)
----------------	----------------	--------------------	--------------------	--------------------

QSNM12EG	592930	4400N	4700N	4900N
QSNM8EG	592910	3300N	3300N	3300N
QSNM10EG	592920	4400N	4400N	4900N
QSNM6EG	592900	2000N	2000N	2000N

ADDITIONAL PRODUCT DETAILS

Static Load 1 represents 1.5 mm strut channel thickness. Static Load 2 represents 2.0 mm strut channel thickness. Static Load 3 represents 2.5 mm strut channel thickness.

DIAGRAMS

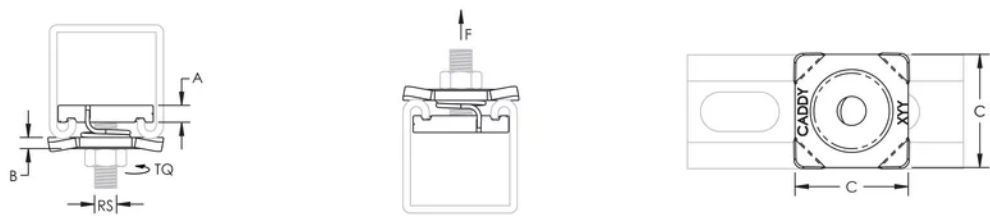

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

