

Speedway Cable Ladder Flat Elbow, 90°



CERTIFICATIONS



FEATURES

Creates a 90° corner change in cable tray direction

Provides optimal support for high-performance low voltage and data cables

Innovative SPEEDLOK integrated coupling system

Safety edge protects cables during installation

Slotted side channel, eliminating field drilling for cut-to-length applications

IEC 61537 load rating and earthing compliant

Responsive design and layout services, including seismic

SPECIFICATIONS

Finish: Hot-Dip Galvanized


Material: Сталь

Table 1/1

Catalog Number	Article Number	Width (W)	Angle (a)	A	B	C
----------------	----------------	-----------	-----------	---	---	---

CL110X900FE9 OHD	840250	900 mm	90 °	1295 mm	1295 mm	80 mm
CL110X600FE9 OHD	840230	600 mm	90 °	995 mm	995 mm	80 mm
CL110X750FE9 OHD	840240	750 mm	90 °	1145 mm	1145 mm	80 mm
CL110X450FE9 OHD	840220	450 mm	90 °	845 mm	845 mm	80 mm
CL110X150FE9 OHD	840200	150 mm	90 °	545 mm	545 mm	80 mm
CL110X300FE9 OHD	840210	300 mm	90 °	695 mm	695 mm	80 mm

DIAGRAMS

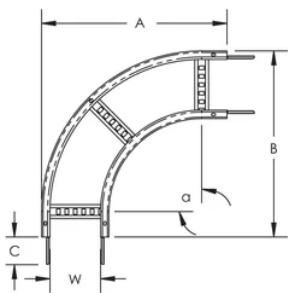

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

