


# Joint Bond T8 Complete Welder Pair, Power, 50 mm<sup>2</sup> Ropelay

## Data Solutions

### CATALOG NUMBER

**PBCT8X3**

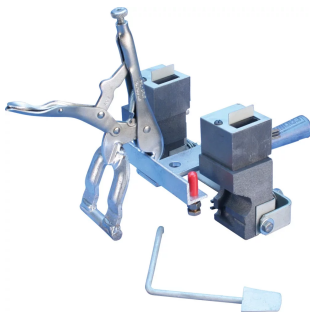

### FEATURES

Complete welder assembly provides a convenient means of attaching jumper bonds to the head of the rail

Connection is made within the confines of the splice plate

Includes mold cleaner and flint ignitor

### PRODUCT ATTRIBUTES

Material: Graphite; Сталь; Thermoplastic

Rail Type: 85 lb to 141 lb T-Rail Sections

Bond Terminal Style: C

Conductor Size: 50 mm<sup>2</sup> Ropelay

Conductor Outer Diameter, Nominal: 9.13mm

Bond Length: 177.8mm

Welder Style: T8

Mold Only: Her

Replacement Mold: PBCX3

Welding Material: PB45, Sold Separately

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

⚠ WARNING: This product can expose you to chemicals including diisononyl phthalate, which is known to the State of California to cause cancer. For more information go to [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov).



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**