


Монтажный кронштейн для шины 1, 2- полюсная

Data Solutions

CATALOG NUMBER

20100-028

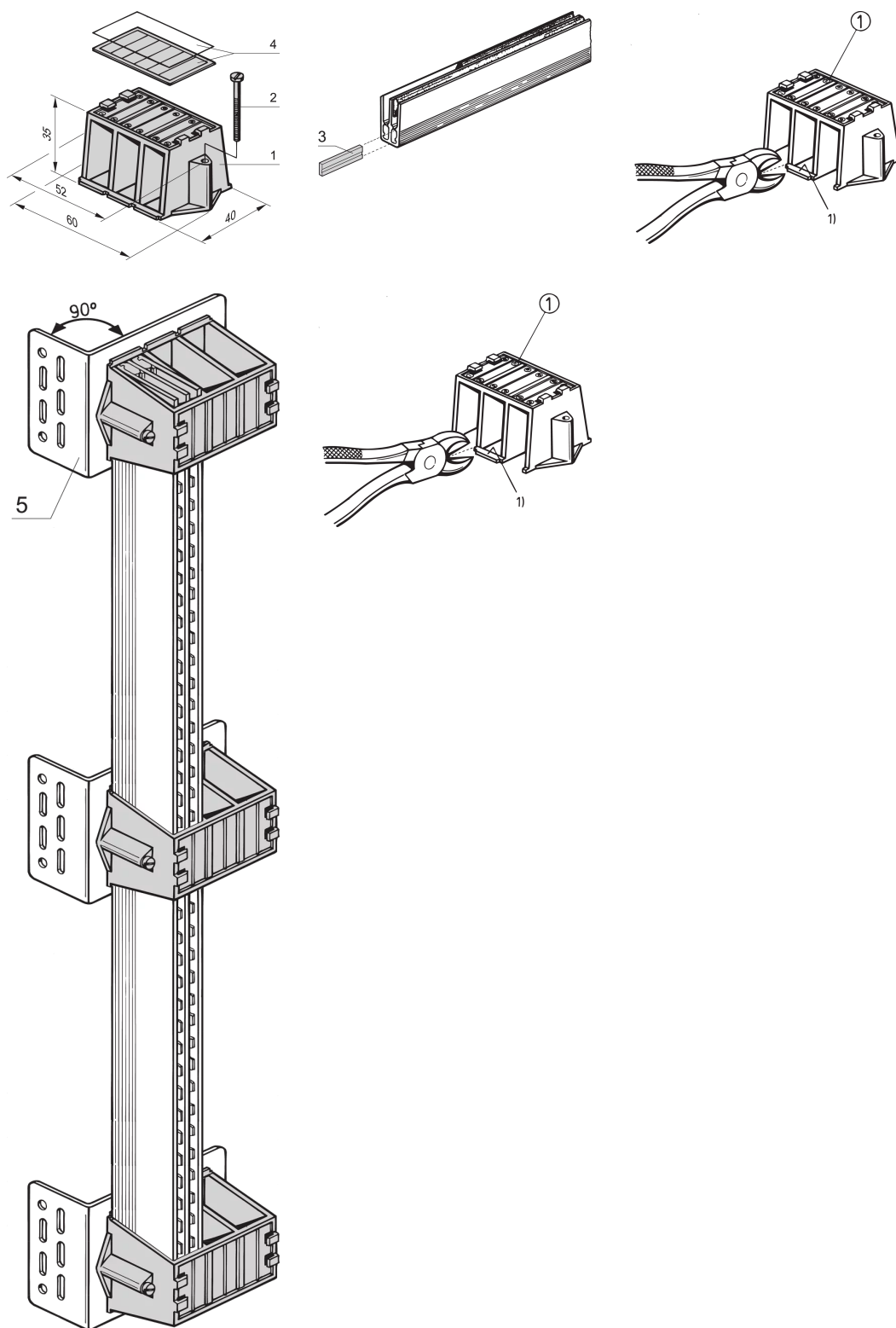

Монтажные кронштейны для шин или модулей шин представляют собой изолированные от цепи нагрузки монтажные блоки для направляющих реек заземления. Также доступны адаптеры с заданными номинальными токами, которые подают ток нагрузки на загрузочные устройства через проводные соединения.

CERTIFICATIONS

RoHS
COMPLIANT

EAC

FEATURES

Монтажный кронштейн для шины, 2-полюсный

PRODUCT ATTRIBUTES

Product Type: Bracket

Type: Mounting Bracket

Works With: Токоведущая шина

Material: Polyphenylene Ether

Package Quantity: 4

Net Weight: 0.07kg

ADDITIONAL PRODUCT DETAILS

По соображениям устойчивости крепежный кронштейн должен устанавливаться с интервалом в 500 мм.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE