

PEMSA Wire Basket Tray L Bracket

Data Solutions



CERTIFICATIONS



FEATURES

Easy to use, quick connect feature

Ideal for typical wall and channel installations

IEC 61537 load rating and earthing compliant

SPECIFICATIONS

Finish: Electrogalvanized


Material: Сталь

Table 1/1

Catalog Number	Article Number	Длина мм (L)	Width (W)	Height (H)	Static Load	Certifications
WBT200LBRKT	820220	270mm	54mm	138mm	588N	

CatalogNumber	Article Number	Длина мм (L)	Width (W)	Height (H)	Static Load	Certifications
WBT100LBRKT	820200	170mm	54mm	138mm	588N	DoP, CADDY EU WBT, CE, CADDY EU WBT BRT, ANOR EU WTB B S
WBT300LBRKT	820230	370mm	54mm	138mm	373N	ANOR EU WTB B S, CE, CADDY EU WBT BRT, DoP, CADDY EU WBT, UKCA, CADDY EU WTB B
WBT400LBRKT	820240	470mm	54mm	138mm	275N	CE, CADDY EU WBT BRT, ANOR EU WTB B S, DoP, CADDY EU WBT, UKCA, CADDY EU WTB B
WBT150LBRKT	820210	220mm	54mm	138mm	588N	DoP, CADDY EU WBT, ANOR EU WTB B S, CE, CADDY EU WBT BRT

DIAGRAMS

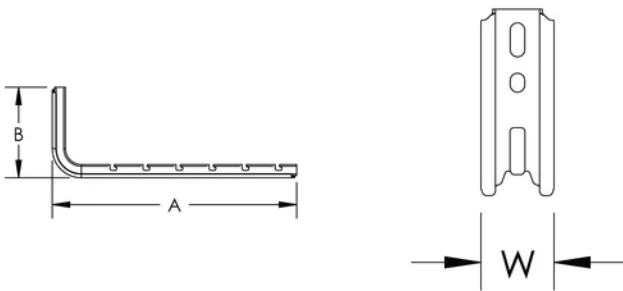

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE