

Cross Round Connector



FEATURES

Can be used for parallel or cross-run connections

SPECIFICATIONS


Table 1/2

Catalog Number	Article Number	Material	Finish	Conductor Size	Глубина мм (D)	Width (W)
CCR608S		Stainless Steel 18-8 (EN 1.4305)		6 mm Solid, 8 mm Solid, 8 mm Stranded	38.1mm	38.1 mm
CCR68CU	101260	Copper		6 mm Solid, 8 mm Solid, 8 mm Stranded	28mm	28 mm
CCR68GS	101265	Сталь	Hot-Dip Galvanized	6 mm Solid, 8 mm Solid, 8 mm Stranded	41mm	41 mm

Table 2/2

Catalog Number	Article Number	Unit Weight
CCR608S		0.05 kg
CCR68CU	101260	0.05 kg
CCR68GS	101265	0.14 kg

DIAGRAMS

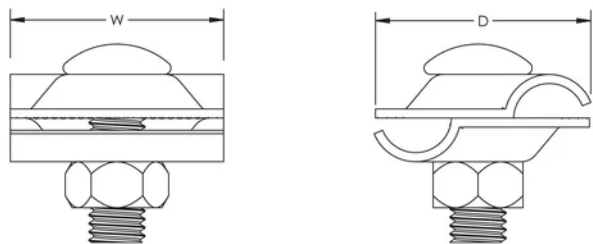

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE