


Cable to Web of Rail Replacement Mold Pair, Signal, 85-141 lb T-Rail, 1" Tab Bond Terminal Style, 10 mm² Stranded

CATALOG NUMBER

SBB200R

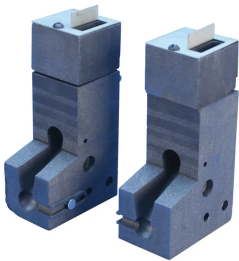

FEATURES

Replacement mold pair designed for the installation of track circuits and jumper bonds to the neutral axis

Sold in pairs

PRODUCT ATTRIBUTES

Material: Graphite

Rail Type: 85 lb to 141 lb T-Rail Sections

Bond Terminal Style: 1" Tab

Conductor Size: 10 mm² Stranded

Conductor Outer Diameter, Nominal: 4.12mm

Welder Style: TB5;T21

Bond Clips Included: Her

Mold Only: Да

Welding Material: SB25, Sold Separately

Conductor Sleeve: SBS10, Sold Separately

Bond Clip: B33810

Hammer Die: SBD12, Sold Separately

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE