

ISONV Adjustable Offset Mast Bracket



FEATURES

Telescoping mast support for mounting under roof overhang

Adjustable mounting legs for level mast installation

SPECIFICATIONS



Table 1/2

Catalog Number	Material	Длина мм (L)	Length	Diameter (Ø)	Hole Size (HS)	A
ISONVBKTXL	Stainless Steel 304 (EN 1.4301)	800mm	800 - 1000 mm	40 - 50 mm	11 mm	240 mm

Table 2/2

Catalog Number	B	Angle (a)
ISONVBKTXL	182 mm	45 °

DIAGRAMS

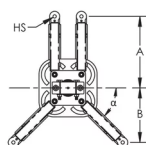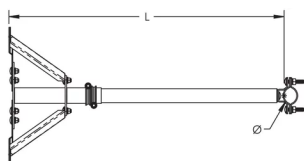

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE