

EBC-133 Main Terminal Clamp Kit



CERTIFICATIONS



FEATURES

Kit includes 10 clamps and 20 screws

Used to connect thicker conductors including IBSB25 Insulated Braided Conductor, MBJ Grounding and Bonding Braid, and nVent ERIFLEX Flexibar up to 9 mm (0.354")

Quick and easy installation

RoHS compliant

SPECIFICATIONS

Table 1/2


Catalog Number	Article Number	Material	Finish	Conductor Size, IEC	Width (W)	Thickness (T)
KIT-EBC133-15	568614	Сталь	Electrogalvanized	16 - 35 mm ²	25 mm	2.5 mm

Table 2/2

Catalog Number	Article Number	A	Hole Size (HS)	Thread Size (TS)	Unit Weight	Глубина мм (D)
----------------	----------------	---	----------------	------------------	-------------	----------------

KIT-EBC133-15	568614	15 mm	5.5 mm	M5	0.01 kg	10mm
---------------	--------	-------	--------	----	---------	------

DIAGRAMS

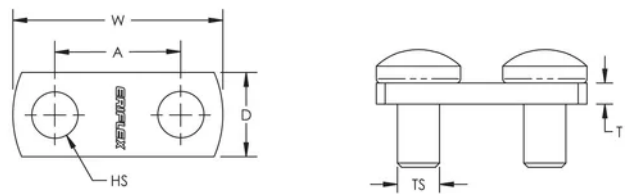

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
 Option 1 – Customer Care
 Option 2 – Technical Support

Europe

Netherlands:
 +31 800-0200135
 France:
 +33 800 901 793

Europe

Germany:
 800 1890272
 Other Countries:
 +31 13 5835404

APAC

Shanghai:
 + 86 21 2412 1618/19
 Sydney:
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE