


## , CAC

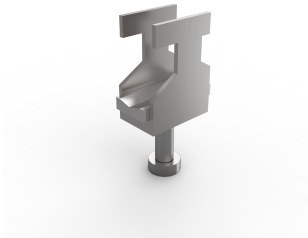

The cable clamps secures cables into position and relieves any external strains which in turn helps prevent equipment damage.

### FEATURES

---

Description: To secure incoming cables onto the fixing bars CAB and CABP. Holds the cable in position and supports the weight.

Material: Zinc plated steel.

Pack quantity: 25 clamps.

Mounting requirements: Add CAB/CABP to mount the cable clamps CAC.

## SPECIFICATIONS

**Thickness:** 2mm  
**Material:** Mild Steel  
**Finish:** Zinc Plated

Table 1/1

| Catalog Number | Высота мм | Ширина мм | Глубина мм | Enclosure Material               | Product Family | Cable Diameter Range |
|----------------|-----------|-----------|------------|----------------------------------|----------------|----------------------|
| CAC0612        | 64mm      | 25mm      | 19mm       | Mild Steel,<br>Нержавеющая сталь | Free-Standing  | 6 – 12mm             |
| CAC1014        | 64mm      | 25mm      | 19mm       | Mild Steel,<br>Нержавеющая сталь | Free-Standing  | 10 – 14mm            |
| CAC1216        | 64mm      | 25mm      | 19mm       | Mild Steel,<br>Нержавеющая сталь | Free-Standing  | 12 – 16mm            |
| CAC5864        | 64mm      | 25mm      | 19mm       | Mild Steel,<br>Нержавеющая сталь | Free-Standing  | 58 – 64mm            |
| CAC1418        | 64mm      | 25mm      | 19mm       | Mild Steel,<br>Нержавеющая сталь | Free-Standing  | 14 – 18mm            |
| CAC1822        | 64mm      | 25mm      | 19mm       | Mild Steel,<br>Нержавеющая сталь | Free-Standing  | 18 – 22mm            |
| CAC2226        | 64mm      | 25mm      | 19mm       | Mild Steel,<br>Нержавеющая сталь | Free-Standing  | 22 – 26mm            |
| CAC2630        | 64mm      | 25mm      | 19mm       | Mild Steel,<br>Нержавеющая сталь | Free-Standing  | 26 – 30mm            |
| CAC3034        | 64mm      | 25mm      | 19mm       | Mild Steel,<br>Нержавеющая сталь | Free-Standing  | 30 – 34mm            |
| CAC3438        | 64mm      | 25mm      | 19mm       | Mild Steel,<br>Нержавеющая сталь | Free-Standing  | 34 – 38mm            |
| CAC3842        | 64mm      | 25mm      | 19mm       | Mild Steel,<br>Нержавеющая сталь | Free-Standing  | 38 – 42mm            |
| CAC4246        | 64mm      | 25mm      | 19mm       | Mild Steel,<br>Нержавеющая сталь | Free-Standing  | 42 – 46mm            |

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper

installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**