


„ CBPS

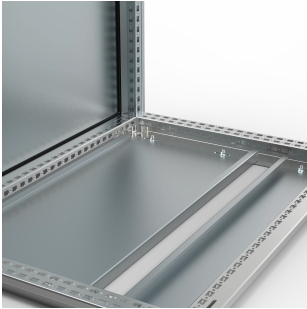

A split bottom plate offers a flexible cabling solution and eliminates the need for individual cable glands. The protection degree is maintained by using a separate gasket.

FEATURES

Description: Fitted in place of the standard one piece bottom plate, allows direct cable entry. To achieve perfect sealing around the cables use the gasket kit BG01.

Material: AISI 304 / AISI 316L pre-grained stainless steel.

Bottom plates: 1.5 mm.

Finish: 400 pre-grained stainless steel.

Pack quantity: 1 kit of two part bottom plate.

SPECIFICATIONS

Thickness: 1.5mm
Finish: Brushed

Table 1/1

Catalog Number	Высота мм	Ширина мм	Глубина мм	Enclosure Material	Material	Quick Ship
CBPS0640	25mm	600mm	400mm	Нержавеющая сталь	Stainless Steel 304	No
CBPS0640-316	25mm	600mm	400mm	Нержавеющая сталь	Stainless Steel 316	No
CBPS0650	25mm	600mm	500mm	Нержавеющая сталь	Stainless Steel 304	No
CBPS0650-316	25mm	600mm	500mm	Нержавеющая сталь	Stainless Steel 316	No
CBPS0660	25mm	600mm	600mm	Нержавеющая сталь	Stainless Steel 304	No
CBPS0660-316	25mm	600mm	600mm	Нержавеющая сталь	Stainless Steel 316	No
CBPS0840	25mm	800mm	400mm	Нержавеющая сталь	Stainless Steel 304	No
CBPS0840-316	25mm	800mm	400mm	Нержавеющая сталь	Stainless Steel 316	No
CBPS0850	25mm	800mm	500mm	Нержавеющая сталь	Stainless Steel 304	No
CBPS0850-316	25mm	800mm	500mm	Нержавеющая сталь	Stainless Steel 316	No
CBPS0860	25mm	800mm	600mm	Нержавеющая сталь	Stainless Steel 304	No
CBPS0860-316	25mm	800mm	600mm	Нержавеющая сталь	Stainless Steel 316	No
CBPS1040	25mm	1000mm	400mm	Нержавеющая сталь	Stainless Steel 304	No
CBPS1040-316	25mm	1000mm	400mm	Нержавеющая сталь	Stainless Steel 316	No
CBPS1050	25mm	1000mm	500mm	Нержавеющая сталь	Stainless Steel 304	No
CBPS1050-316	25mm	1000mm	500mm	Нержавеющая сталь	Stainless Steel 316	No
CBPS1060	25mm	1000mm	600mm	Нержавеющая сталь	Stainless Steel 304	No

Catalog Number	Высота мм	Ширина мм	Глубина мм	EnclosureMaterial	Material	Quick Ship
CBPS1060-316	25mm	1000mm	600mm	Нержавеющая сталь	Stainless Steel 316	No

ADDITIONAL PRODUCT DETAILS

For enclosures 1200 mm & 1600 mm wide use 2 x 600 mm & 2 x 800 mm wide bottom plates.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE