


Front Panel, Front anodized, Rear Conductive, Unshielded, 3 U, 84 HP

Power Utilities

CATALOG NUMBER

30838-123

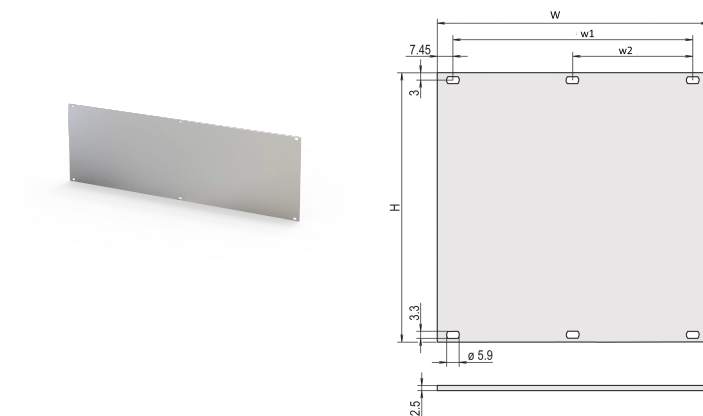

Front panel, unshielded, front anodized and rear conductive.

CERTIFICATIONS



FEATURES

Partial width front panel, Al, 2.5 mm

Al, front anodized, conductive

PRODUCT ATTRIBUTES

Product Type: Передняя панель

Type: Front Panel without Handle

Handle Type: Нет

Mounting: Screw-on Front

EMC Shielding: Нет

Material: Алюминий

Front Finish: Anodized

Rear Finish: Conductive

Treated Edges: Нет

Rack Height: 3 U

Высота мм: 128.4 mm

Rack Width: 84 HP

Ширина мм: 426.4 mm

Complies With: IEC 60297-3-101; IEEE 1101.1/10

Package Quantity: 1

ADDITIONAL PRODUCT DETAILS

Please order fixing material (sleeves, collar screws) separately.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE