


RackPower iPDU, RP1326, 100-240 VAC, 1-phase

Power Utilities

CATALOG NUMBER

RP1326

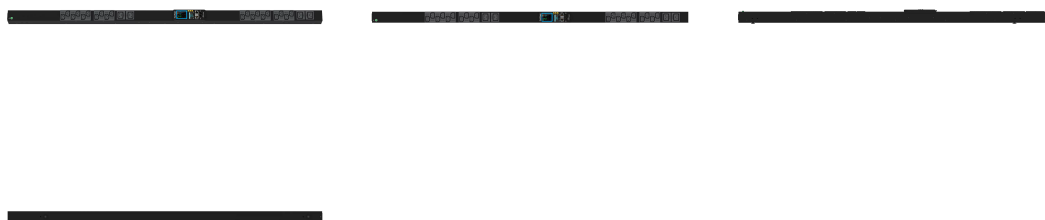

Modular, compact intelligent PDU with inlet metering. Ultra-Low Profile Design with only 44 mm height.

FEATURES

RackPower RP1xxx Intelligent Power Distribution Units monitors input power of the entire PDU, provides billing grade unit level monitoring

High Visibility Data Display and Interactive Graphic Display

Measure circuit breaker loads across redundant feeds to avoid accidental downtime

Enables smart load balancing for power efficiency and maximized capacity utilization

Gigabit Ethernet Interface and redundant Ethernet (10/100)

iPDU DC power redundancy solution for up to 64 PDU's

Toolless Hot-Swap Controller

Input Voltage Range 100 - 240 VAC, 1-phase L-N or L-L

Input connector C20

C13, C19 outlets

PRODUCT ATTRIBUTES

Product Type: Панели электропитания

Socket Type: IEC C13; IEC C19

Color: Черный

Длина мм: 1490 mm

Voltage AC: 208 V

Function: Input Monitored

Глубина мм: 53 mm

Ширина мм: 52 mm

ADDITIONAL PRODUCT DETAILS

Please order bracket for vertical mounting separately.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE