


EuropacPRO 19" Subrack Kit for Backplane, Light, Unshielded

Power Utilities

Non-EMC shielded subrack for backplane mounting, light version.

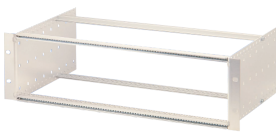

CERTIFICATIONS



FEATURES

Subrack with side panel type L ("light") with integrated 19" support brackets

Horizontal rail type "light"

Aluminum construction

Rear horizontal rails for backplane mounting with insulation strip

Installed load up to 7.5 kg

Supplied as space-saving flat-pack

Internal and external dimensions in accordance with: IEC 60297-3-100, -101, IEEE 1101.1

Modifications such as cutouts, different finishes or dimensions available

SPECIFICATIONS

Table 1/2

Catalog Number	Rack Height	Глубина мм	Package Quantity	For Mounting	Board Depth	Handle Included
24564-433	6 U	295 mm	1	Объединительная плата	160 mm, 220 mm, 280 mm	Нет
24564-432	6 U	235 mm	1	Объединительная плата	160 mm, 220 mm	Нет
24564-431	6 U	175 mm	1	Объединительная плата	160 mm	Нет
24564-133	3 U	295 mm	1	Объединительная плата	160 mm, 220 mm, 280 mm	Нет
24564-132	3 U	235 mm	1	Объединительная плата	160 mm, 220 mm	Нет
24564-131	3 U	175 mm	1	Объединительная плата	160 mm	Нет

Table 2/2

Catalog Number	Mounting	Complies With	EMC Shielding	Product Type	Rack Width	Static Load
24564-433	Rack	IEC 60297-3-100, IEC 60297-3-101, IEEE 1101.1	Нет	Subrack/Chassis	84 HP	7.5 kgf
24564-432	Rack	IEC 60297-3-100, IEC 60297-3-101, IEEE 1101.1	Нет	Subrack/Chassis	84 HP	7.5 kgf
24564-431	Rack	IEC 60297-3-100, IEC 60297-3-101, IEEE 1101.1	Нет	Subrack/Chassis	84 HP	7.5 kgf
24564-133	Rack	IEC 60297-3-100, IEC 60297-3-101, IEEE 1101.1	Нет	Subrack/Chassis	84 HP	7.5 kgf
24564-132	Rack	IEC 60297-3-100, IEC 60297-3-101, IEEE 1101.1	Нет	Subrack/Chassis	84 HP	7.5 kgf
24564-131	Rack	IEC 60297-3-100, IEC 60297-3-101, IEEE 1101.1	Нет	Subrack/Chassis	84 HP	7.5 kgf

ADDITIONAL PRODUCT DETAILS

Subrack is not prepared for shielding, retrofit for protection class IP 20 possible

Individual configuration: broad range of variants in height, width and depth; guide rails for a wide variety of applications; interior options; accessories and mounting material.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE