


Front Panel, Unshielded, Bottom Hinged

Power Utilities

Unshielded front panel bottom hinged.

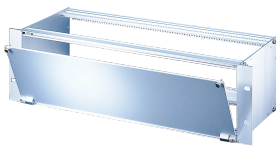

CERTIFICATIONS



FEATURES

Front panel can be unhinged at 135° (not RatiopacPRO) opening angle

Enables mounting on horizontal rails

SPECIFICATIONS

Table 1/3

Catalog Number	Rack Height	Rack Width	Package Quantity	Mounting	Front Finish	Rear Finish
20838-280	3 U	28 HP	1	Hinged, Bottom	Anodized	Conductive
20838-276	6 U	84 HP	1	Hinged, Bottom	Anodized	Conductive
20838-275	6 U	63 HP	1	Hinged, Bottom	Anodized	Conductive

CatalogNumber	Rack Height	Rack Width	Package Quantity	Mounting	Front Finish	Rear Finish
20838-277	4 U	42 HP	1	Hinged, Bottom	Anodized	Conductive
20838-274	6 U	42 HP	1	Hinged, Bottom	Anodized	Conductive
20838-273	3 U	84 HP	1	Hinged, Bottom	Anodized	Conductive
20838-278	4 U	63 HP	1	Hinged, Bottom	Anodized	Conductive
20838-272	3 U	63 HP	1	Hinged, Bottom	Anodized	Conductive
20838-279	4 U	84 HP	1	Hinged, Bottom	Anodized	Conductive
20838-271	3 U	42 HP	1	Hinged, Bottom	Anodized	Conductive

Table 2/3

Catalog Number	Treated Edges	Complies With	EMC Shielding	Высота мм	Material	Product Type
20838-280	Нет	IEC 60297-3-101, IEEE 1101.1/10	Нет	128.4 mm	Алюминий	Передняя панель
20838-276	Нет	IEC 60297-3-101, IEEE 1101.1/10	Нет	261.8 mm	Алюминий	Передняя панель
20838-275	Нет	IEC 60297-3-101, IEEE 1101.1/10	Нет	261.8 mm	Алюминий	Передняя панель
20838-277	Нет	IEC 60297-3-101, IEEE 1101.1/10	Нет	172.9 mm	Алюминий	Передняя панель
20838-274	Нет	IEC 60297-3-101, IEEE 1101.1/10	Нет	261.8 mm	Алюминий	Передняя панель
20838-273	Нет	IEC 60297-3-101, IEEE 1101.1/10	Нет	128.4 mm	Алюминий	Передняя панель
20838-278	Нет	IEC 60297-3-101, IEEE 1101.1/10	Нет	172.9 mm	Алюминий	Передняя панель

CatalogNumber	Treated Edges	Complies With	EMC Shielding	Высота мм	Material	Product Type
20838-272	Нет	IEC 60297-3-101, IEEE 1101.1/10	Нет	128.4 mm	Алюминий	Передняя панель
20838-279	Нет	IEC 60297-3-101, IEEE 1101.1/10	Нет	172.9 mm	Алюминий	Передняя панель
20838-271	Нет	IEC 60297-3-101, IEEE 1101.1/10	Нет	128.4 mm	Алюминий	Передняя панель

Table 3/3

Catalog Number	Type	Ширина мм
20838-280	Front Panel without Handle	141.9 mm
20838-276	Front Panel without Handle	426.4 mm
20838-275	Front Panel without Handle	319.7 mm
20838-277	Front Panel without Handle	213 mm
20838-274	Front Panel without Handle	213 mm
20838-273	Front Panel without Handle	426.4 mm
20838-278	Front Panel without Handle	319.7 mm
20838-272	Front Panel without Handle	319.7 mm
20838-279	Front Panel without Handle	426.4 mm
20838-271	Front Panel without Handle	213 mm

ADDITIONAL PRODUCT DETAILS

Front panel can be removed in opened position (> 135°).

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper

installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE