

19-дюймовая передняя панель с отверстиями под ручки



Оформите фасады и боковые границы устройств с помощью 19-дюймовых передних панелей SCHROFF. 19-дюймовые передние панели SCHROFF имеют дополнительные отверстия для крепления ручки и доступны в диапазоне от 1 U до 6 U.

CERTIFICATIONS



FEATURES

19" передние панели с дополнительными отверстиями для ручек

SPECIFICATIONS

Rack Width:	95HP
Material:	Алюминий
Аксессуар Тип:	Передняя панель
Product Type:	Передняя панель

Table 1/3

Catalog Number	Rack Height	Глубина мм (D)	Handle Type	Finish	Mounting	Package Quantity
30219-161	1U	3mm	Front Handle	Anodized	Screw-on Front	1
40304-050	1U	3mm	Front Handle	Anodized	Screw-on Front	1

CatalogNumber	Rack Height	Глубина мм(D)	Handle Type	Finish	Mounting	Package Quantity
30219-162	2U	3mm	Front Handle	Anodized	Screw-on Front	1
30219-163	3U	3mm	Front Handle	Anodized	Screw-on Front	1
30219-164	4U	3mm	Front Handle	Anodized	Screw-on Front	1
30219-165	5U	3mm	Front Handle	Anodized	Screw-on Front	1
30219-166	6U		Front Handle	Anodized	Screw-on Front	1
40304-051	2U	3mm	Front Handle	Anodized	Screw-on Front	1
40304-052	3U	3mm	Front Handle	Anodized	Screw-on Front	1
40304-053	4U	3mm	Front Handle	Anodized	Screw-on Front	1
40304-054	5U	3mm	Front Handle	Anodized	Screw-on Front	1
40304-055	6U	3mm	Front Handle	Anodized	Screw-on Front	1

Table 2/3

Catalog Number	Front Finish	Rear Finish	Treated Edges	EMC Shielding	Высота мм (H)	Type
30219-161	Anodized	Anodized	Нет	Нет	43.6mm	19" Front Panel
40304-050	Anodized	Anodized	Да	Нет	43.6mm	19" Front Panel
30219-162	Anodized	Anodized	Нет	Нет	88.1mm	19" Front Panel
30219-163	Anodized	Anodized	Нет	Нет	132.5mm	19" Front Panel
30219-164	Anodized	Anodized	Нет	Нет	177mm	19" Front Panel
30219-165	Anodized	Anodized	Нет	Нет	221.4mm	19" Front Panel


CatalogNumber	Front Finish	Rear Finish	Treated Edges	EMC Shielding	Высота мм (H)	Type
30219-166	Anodized	Anodized	Нет	Нет	265.9mm	19" Front Panel
40304-051	Anodized	Anodized	Да	Нет	88.1mm	19" Front Panel
40304-052	Anodized	Anodized	Да	Нет	132.5mm	19" Front Panel
40304-053	Anodized	Anodized	Да	Нет	177mm	19" Front Panel
40304-054	Anodized	Anodized	Да	Нет	221.4mm	19" Front Panel
40304-055	Anodized	Anodized	Да	Нет	265.9mm	19" Front Panel

Table 3/3

Catalog Number	Ширина мм (W)	Quick Ship
30219-161	483mm	No
40304-050	483mm	No
30219-162	483mm	No
30219-163	483mm	No
30219-164	483mm	No
30219-165	483mm	No
30219-166	483mm	No
40304-051	483mm	No
40304-052	483mm	No
40304-053	483mm	No
40304-054	483mm	No

Catalog Number	Ширина мм (W)	Quick Ship
40304-055	483mm	No

DIAGRAMS

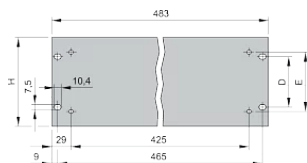

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE