


19-дюйм. нагнетательный вентилятор, 3 U, осевой

Лоток вентилятора со встроенным нагнетательным вентилятором.

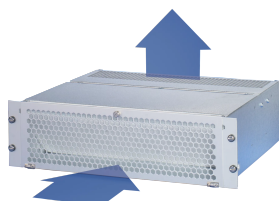

CERTIFICATIONS



FEATURES

Действие системы вентиляции направлено точно на электронику

19-дюйм. нагнетательный вентилятор, 3 U, осевой

Подача воздуха спереди, выпуск воздуха через верхнюю заднюю часть шкафа (направляется вверх заглушками или через шланги в заднюю часть и вверх)

Защита от прикосновения в соответствии с DIN EN ISO 13857

SPECIFICATIONS

Table 1/1

Catalog Number	Input Voltage AC	Package Quantity	Finish	Material	Quick Ship
10713-546	230V	1	Aluminum-Zinc Plated	Сталь, Алюминий	No
10713-547	115V min	1	Aluminum-Zinc Plated	Сталь, Алюминий	No

ADDITIONAL PRODUCT DETAILS

С заглушками, вентилятор может быть модернизирован под различные концепции охлаждения

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE