


Передняя панель АМС с натяжной ручкой

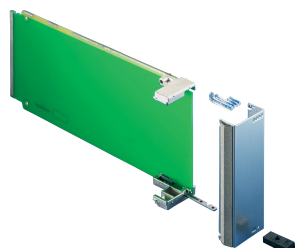

Передняя панель AdvancedMC с прокладкой для защиты от электромагнитных помех для модулей AMC.0 Rev. 2.0.

CERTIFICATIONS



FEATURES

В соответствии со спецификацией AMC.0 R2.0

Передняя панель для механизма вытяжной ручки (с выемками для световода)

Для использования вместе с механизмом вытяжной ручки AMC, AMC.0 R2.0

SPECIFICATIONS

Аксессуар Тип: Передняя панель


Product Type: Передняя панель

Table 1/2

Catalog Number	Высота мм (H)	Rack Width	Design Feature	Material	Finish	Package Quantity
30849-402	73.8mm	3HP	Compact	Нержавеющая сталь		1
30849-403	73.8mm	4HP	Mid-Size	Нержавеющая сталь		1
30849-404	73.8mm	6HP	Full-Size	Нержавеющая сталь		1

CatalogNumber	Высота мм (H)	Rack Width	Design Feature	Material	Finish	Package Quantity
30849-406	148.8mm	4HP	Mid-Size	Нержавеющая сталь		1
30849-407	148.8mm	6HP	Full-Size	Нержавеющая сталь		1
30849-658	73.8mm	4HP	Mid-Size	Алюминий	Passivated	1
30849-670	148.8mm	4HP		Алюминий	Passivated	1
30849-682	73.8mm	6HP	Full-Size	Алюминий	Passivated	1
30849-694	148.8mm	6HP	Full-Size	Алюминий	Passivated	1

Table 2/2					
Catalog Number	Front Finish	Rear Finish	Глубина мм (D)	Ширина мм (W)	Quick Ship
30849-402	Raw	Raw	1mm	13.9mm	No
30849-403	Raw	Raw	1mm	19mm	No
30849-404	Raw	Raw	1mm	29mm	No
30849-406	Raw	Raw	1mm	19mm	No
30849-407	Raw	Raw	1mm	29mm	No
30849-658	Raw	Raw	2.5mm	19mm	No
30849-670	Raw	Raw	2.5mm	19mm	No
30849-682	Raw	Raw	2.5mm	29mm	No
30849-694	Raw	Raw	2.5mm	29mm	No

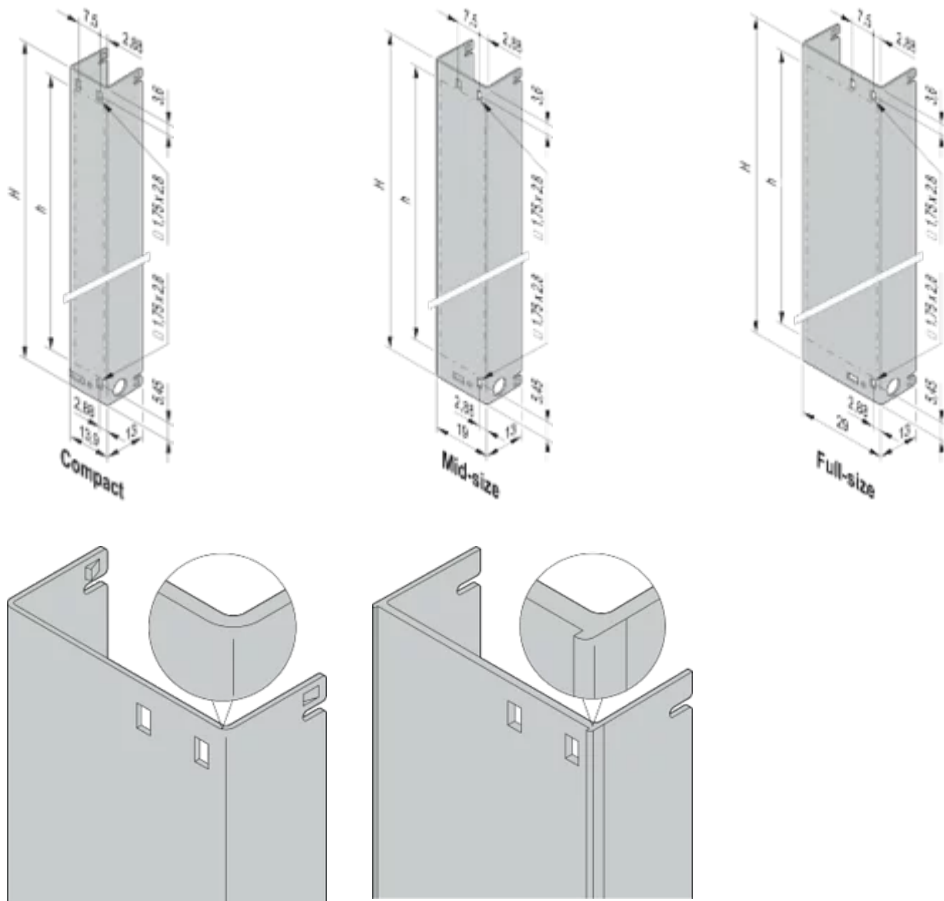

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE