


# Инструменты для компонентов повышенной прочности

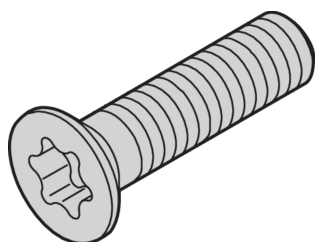

Детали для сборки с резьбовым соединением для прочной боковой панели, горизонтальной рейки, заглушек, заднего уголка.

## CERTIFICATIONS



## FEATURES

Винты для следующих креплений: прочная боковая панель — горизонтальная рейка, Прочная боковая панель — заглушка, прочная боковая панель — задний уголок

## SPECIFICATIONS

**Product Type:** Монтажные детали

**Product Family:** EuropacPRO

Table 1/2

| Catalog Number | Type              | Длина мм | Package Quantity | Thread Size | Finish      | Material          |
|----------------|-------------------|----------|------------------|-------------|-------------|-------------------|
| 24566-105      | Countersunk Screw | 7mm      | 100              | M4          |             | Нержавеющая сталь |
| 24560-140      | Square Nut        |          | 100              |             | Zinc Plated | Сталь             |
| 24566-106      | Countersunk Screw | 10mm     | 100              | M4          |             | Нержавеющая сталь |

| CatalogNumber | Type              | Длина мм | Package Quantity | Thread Size | Finish | Material          |
|---------------|-------------------|----------|------------------|-------------|--------|-------------------|
| 24566-101     | Countersunk Screw | 14mm     | 100              | M4          |        | Нержавеющая сталь |
| 24566-100     | Countersunk Screw | 18mm     | 100              | M4          |        | Нержавеющая сталь |
| 24566-104     | Panhead Screw     | 8mm      | 100              | M4          |        | Нержавеющая сталь |
| 24566-103     | Panhead Screw     | 10mm     | 100              | M4          |        | Нержавеющая сталь |
| 24566-102     | Panhead Screw     | 14mm     | 100              | M4          |        | Нержавеющая сталь |

Table 2/2

| Catalog Number | Works With     | Quick Ship |
|----------------|----------------|------------|
| 24566-105      | Блочный каркас | No         |
| 24560-140      | Блочный каркас | No         |
| 24566-106      | Блочный каркас | No         |
| 24566-101      | Блочный каркас | No         |
| 24566-100      | Блочный каркас | No         |
| 24566-104      | Блочный каркас | No         |
| 24566-103      | Блочный каркас | No         |
| 24566-102      | Блочный каркас | No         |

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**