


Объединительная плата с соединенными сигнальными линиями

Объединительная плата с соединенными сигнальными линиями

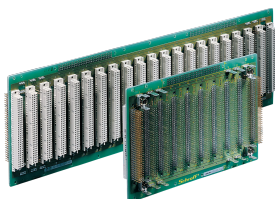

CERTIFICATIONS



FEATURES

Возможность подачи питания на каждый слот (ряд 1 + 32)

Адаптационные поля для подключения питания на двухслойных объединительных платах

SPECIFICATIONS

Table 1/2

Catalog Number	Product Type	Number of Slots	Rack Height	Backplane Type	Slot Width	Connector Type
23007-421	Объединительная плата	21	3U	90 Signal Lines	4HP	C96F
23007-051	Объединительная плата	21	3U	60 Signal Lines	4HP	C96F
23007-040	Объединительная плата	10	3U	60 Signal Lines	4HP	C96F
23007-410	Объединительная плата	10	3U	90 Signal Lines	4HP	C96F

CatalogNumber	Product Type	Number ofSlots	Rack Height	BackplaneType	Slot Width	ConnectorType
23007-188	Объединительная плата	28	3U	60 Signal Lines	3HP	
23007-010	Объединительная плата	10	3U	60 Signal Lines	4HP	C64F
23007-081	Объединительная плата	21	3U	60 Signal Lines	4HP	
23007-114	Объединительная плата	14	3U	60 Signal Lines	3HP	C64F
23007-158	Объединительная плата	28	3U	60 Signal Lines	3HP	C96F
23007-128	Объединительная плата	28	3U	60 Signal Lines	3HP	C64F
23007-021	Объединительная плата	21	3U	60 Signal Lines	4HP	C64F

Table 2/2

Catalog Number	Power Connector Type	Package Quantity	Quick Ship
23007-421	Fastons 6.3 x 0.8 mm	1	No
23007-051	Fastons 6.3 x 0.8 mm	1	No
23007-040	Fastons 6.3 x 0.8 mm	1	No
23007-410	Fastons 6.3 x 0.8 mm	1	No
23007-188	Fastons 6.3 x 0.8 mm	1	No
23007-010	Fastons 6.3 x 0.8 mm	1	No
23007-081	Fastons 6.3 x 0.8 mm	1	No
23007-114	Fastons 6.3 x 0.8 mm	1	No
23007-158	Fastons 6.3 x 0.8 mm	1	No
23007-128	Fastons 6.3 x 0.8 mm	1	No

Catalog Number	Power Connector Type	Package Quantity	Quick Ship
23007-021	Fastons 6.3 x 0.8 mm	1	No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE