


Винт с проточкой, Крестообразный шлиц / простой шлиц

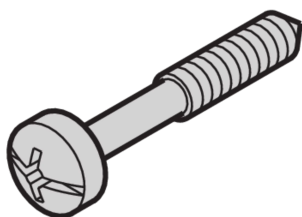

CERTIFICATIONS



SPECIFICATIONS

Type: Screw

Product Type: Screw

Table 1/3

Catalog Number	Diameter	Длина мм	Material	Finish	Package Quantity	Thread Size
21102-026	2.5mm	12.3mm	Сталь	Nickel Plated	100	M2.5
21101-102		12.3mm	Сталь	Zinc Top Coat	100	M2.5
21101-906		12.3mm	Нержавеющая сталь		100	M2.5
21101-101		12.3mm	Сталь	Nickel Plated	100	M2.5
21101-323		11mm			100	M2.5

Table 2/3

Catalog Number	Глубина мм	Высота мм	Ширина мм	Works With	Thread Type	Torque
21102-026				Frame Type Plug-In Unit, Cassettes		0.3N·m
21101-102	14.3mm	5mm	5mm	Передние панели	Metric	0.3N·m
21101-906				Передние панели		0.3N·m
21101-101	14.3mm	5mm	5mm	Передние панели	Metric	0.3N·m
21101-323				Передние панели		

Table 3/3

Catalog Number	Certifications	Quick Ship
21102-026		No
21101-102	RoHS	No
21101-906	RoHS	No
21101-101	RoHS	No
21101-323		No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE