


Передняя/задняя панель CompasPRO, со скрытой фиксацией

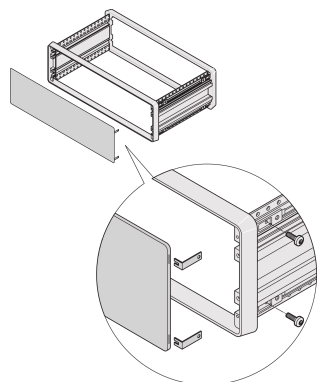

Передняя панель для корпусов CompasPRO крепится к передней раме корпуса. Передняя панель не имеет видимых винтов и может устанавливаться под покрытие из фольги.

CERTIFICATIONS



FEATURES

Алюминиевая панель, 2,5 мм

SPECIFICATIONS

Material:	Алюминий
Finish:	Anodized
Аксессуар Тип:	Передняя панель
Product Type:	Передняя панель

Table 1/2

Catalog Number	Rack Height	Высота мм	Rack Width	Ширина мм	Package Quantity	Front Finish
24575-035	2U	84mm	42HP	238.7mm	1	Anodized

CatalogNumber	Rack Height	Высота мм	Rack Width	Ширина мм	Package Quantity	Front Finish
24575-075	2U	84mm	84HP	452.1mm	1	Anodized
24575-115	3U	128.4mm	28HP	167.5mm	1	Anodized
24575-135	3U	128.4mm	42HP	238.7mm	1	Anodized
24575-155	3U	128.4mm	63HP	345.4mm	1	Anodized
24575-175	3U	128.4mm	84HP	452.1mm	1	Anodized
24575-235	4U	172.9mm	42HP	238.7mm	1	Anodized
24575-255	4U	172.9mm	63HP	345.4mm	1	Anodized
24575-275	4U	172.9mm	84HP	452.1mm	1	Anodized
24575-455	6U	261.8mm	63HP	345.4mm	1	Anodized
24575-475	6U	261.8mm	84HP	452.1mm	1	Anodized

Table 2/2

Catalog Number	Rear Finish	Treated Edges	Глубина мм	Quick Ship
24575-035	Anodized	Нет	2.5mm	No
24575-075	Anodized	Нет	2.5mm	No
24575-115	Anodized	Нет	2.5mm	No
24575-135	Anodized	Нет	2.5mm	No
24575-155	Anodized	Нет	2.5mm	No
24575-175	Anodized	Нет	2.5mm	No
24575-235	Anodized	Нет	2.5mm	No

Catalog Number	Rear Finish	Treated Edges	Глубина мм	Quick Ship
24575-255	Anodized	Нет	2.5mm	No
24575-275	Anodized	Нет	2.5mm	No
24575-455	Anodized	Нет	2.5mm	No
24575-475	Anodized	Нет	2.5mm	No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE