


19-дюймовый настольный корпус Comptec, Без экранирования

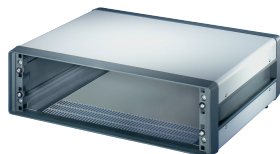

Корпус nVent SCHROFF Comptec совместим с 19-дюймовым шкафом и используется для размещения таких модулей, как 19-дюймовые блочные каркасы, 19-дюймовые лотки вентиляторов или 19-дюймовые передние панели. Этот корпус также обычно используется для настольных систем.

CERTIFICATIONS



FEATURES

Настольный корпус (в сборе)

Без экранирования

Вентиляционные отверстия в нижней крышке

Передняя и задняя рамы из литого под давлением алюминия

Верхняя крышка, нижняя крышка, а также задняя стенка из стали

В соответствии с DIN EN 62368-1

SPECIFICATIONS

Product Type:	Корпус
Type:	Case for 19" Subrack and 19" Chassis
Product Family:	Comptec

Table 1/3

Catalog Number	Rack Height	Высота мм	Rack Width	Глубина мм	Material	Package Quantity
----------------	-------------	-----------	------------	------------	----------	------------------

10225-601	3U	153mm	84HP	300mm	Алюминий, Сталь	1
10225-602	4U	198mm	84HP	300mm	Алюминий, Сталь	1
10225-604	6U	286mm	84HP	300mm	Алюминий, Сталь	1
10225-612	3U	153mm	84HP	400mm	Алюминий, Сталь	1
10225-613	4U	198mm	84HP	400mm	Алюминий, Сталь	1
10225-615	6U	286mm	84HP	400mm	Алюминий, Сталь	1
10225-616	7U	331mm	84HP	400mm	Алюминий, Сталь	1
10225-618	9U	420mm	84HP	400mm	Алюминий, Сталь	1
10225-623	3U	153mm	84HP	500mm	Алюминий, Сталь	1
10225-624	4U	198mm	84HP	500mm	Алюминий, Сталь	1
10225-626	6U	286mm	84HP	500mm	Алюминий, Сталь	1
10225-627	7U	331mm	84HP	500mm	Алюминий, Сталь	1
10225-629	9U	420mm	84HP	500mm	Алюминий, Сталь	1
10225-637	6U	286mm	84HP	600mm	Алюминий, Сталь	1
10225-638	7U	331mm	84HP	600mm	Алюминий, Сталь	1
10225-640	9U	420mm	84HP	600mm	Алюминий, Сталь	1
10225-667	9U	420mm	84HP	400mm	Алюминий	1
10225-670	12U	553mm	84HP	400mm	Алюминий	1
10225-682	9U	420mm	84HP	500mm	Алюминий	1

10225-685	12U	553mm	84HP	500mm	Алюминий	1
10225-693	9U	420mm	84HP	600mm	Алюминий	1
10225-696	12U	553mm	84HP	600mm	Алюминий	1

Table 2/3						
Catalog Number	Usable Height	Usable Width	Front Frame Construction	Cooling Option	Complies With	EMC Shielding
10225-601	134.2mm	451mm	Single Piece	Нет	IEC 60297-3-100	Нет
10225-602	178.7mm	451mm	Single Piece	Нет	IEC 60297-3-100	Нет
10225-604	267.6mm	451mm	Single Piece	Нет	IEC 60297-3-100	Нет
10225-612	134.2mm	451mm	Single Piece	Нет	IEC 60297-3-100	Нет
10225-613	178.7mm	451mm	Single Piece	Нет	IEC 60297-3-100	Нет
10225-615	267.6mm	451mm	Single Piece	Нет	IEC 60297-3-100	Нет
10225-616	312mm	451mm	Single Piece	Нет	IEC 60297-3-100	Нет
10225-618	400.9mm	451mm	Single Piece	Нет	IEC 60297-3-100	Нет
10225-623	134.2mm	451mm	Single Piece	Нет	IEC 60297-3-100	Нет
10225-624	178.7mm	451mm	Single Piece	Нет	IEC 60297-3-100	Нет
10225-626	267.6mm	451mm	Single Piece	Нет	IEC 60297-3-100	Нет
10225-627	312mm	451mm	Single Piece	Нет	IEC 60297-3-100	Нет
10225-629	400.9mm	451mm	Single Piece	Нет	IEC 60297-3-100	Нет
10225-637	267.6mm	451mm	Single Piece	Нет	IEC 60297-3-100	Нет

CatalogNumber	Usable Height	Usable Width	Front Frame Construction	Cooling Option	Complies With	EMC Shielding
10225-638	312mm	451mm	Single Piece	Нет	IEC 60297-3-100	Нет
10225-640	400.9mm	451mm	Single Piece	Нет	IEC 60297-3-100	Нет
10225-667	400.9mm	451mm	Single Piece	Нет	IEC 60297-3-100	Нет
10225-670	534mm	451mm	Single Piece	Нет	IEC 60297-3-100	Нет
10225-682	400.9mm	451mm	Single Piece	Нет	IEC 60297-3-100	Нет
10225-685	534mm	451mm	Single Piece	Нет	IEC 60297-3-100	Нет
10225-693	400.9mm	451mm	Single Piece	Нет	IEC 60297-3-100	Нет
10225-696	534mm	451mm	Single Piece	Нет	IEC 60297-3-100	Нет

Table 3/3					
Catalog Number	Finish	Protection Rating	Static Load	Ширина мм	Quick Ship
10225-601	Powder Coated	IP20	40kg	520mm	No
10225-602	Powder Coated	IP20	40kg	520mm	No
10225-604	Powder Coated	IP20	40kg	520mm	No
10225-612	Powder Coated	IP20	40kg	520mm	No
10225-613	Powder Coated	IP20	40kg	520mm	No
10225-615	Powder Coated	IP20	40kg	520mm	No
10225-616	Powder Coated	IP20	40kg	520mm	No
10225-618	Powder Coated	IP20	40kg	520mm	No
10225-623	Powder Coated	IP20	40kg	520mm	No

Catalog Number	Finish	Protection Rating	Static Load	Ширина мм	Quick Ship
10225-624	Powder Coated	IP20	40kg	520mm	No
10225-626	Powder Coated	IP20	40kg	520mm	No
10225-627	Powder Coated	IP20	40kg	520mm	No
10225-629	Powder Coated	IP20	40kg	520mm	No
10225-637	Powder Coated	IP20	40kg	520mm	No
10225-638	Powder Coated	IP20	40kg	520mm	No
10225-640	Powder Coated	IP20	40kg	520mm	No
10225-667	Powder Coated	IP20	40kg	520mm	No
10225-670	Powder Coated	IP20	40kg	520mm	No
10225-682	Powder Coated	IP20	40kg	520mm	No
10225-685	Powder Coated	IP20	40kg	520mm	No
10225-693	Powder Coated	IP20	40kg	520mm	No
10225-696	Powder Coated	IP20	40kg	520mm	No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE