


# Объединительная плата CPCI PlusIO

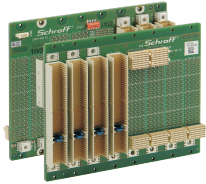

CompactPCI PlusIO сочетает в себе традиционный CompactPCI и новую высокоскоростную технологию CompactPCI Serial на одной объединительной плате. Системный слот CompactPCI PlusIO дополняет как параллельную шину PCI, так и слоты CompactPCI Serial с PCIe, USB, Ethernet и S-ATA.

## CERTIFICATIONS



## FEATURES

В соответствии с: PICMG 2.0 R3.0 CompactPCI Core Specification, Спецификация горячей замены PICMG 2.1 R2.0, PICMG 2.9 R1.0 System Management Bus Specification, PICMG 2.10 R1.0 Keying Specification, Спецификация CompactPCI PlusIO PICMG 2.30 R1.0, Спецификация PICMG CompactPCI Serial (CPCI-S.0 R1.0)

System slot in accordance with PICMG 2.30, 32-bit CPCI bus on P1, PCIe, S-ATA, USB

Периферийные слоты CompactPCI, 32-разрядные с Rear I/O на P2

Задняя панель ввода-вывода на слотах CompactPCI Serial по запросу

Слоты для плат периферийных устройств CompactPCI Serial с PCIe x1, S-ATA и USB

Полносвязный Ethernet на системном слоте и 2 слота CompactPCI Serial, поддерживает 1000Base-T и 10GBase-T

Параметр V (I/O) можно настроить на 3,3 В или 5 В (предустановлено 5 В)

## SPECIFICATIONS

Table 1/3

| Catalog Number | Product Type          | Number of Slots | Rack Height | Backplane Type                       | System Slot | Slot Width |
|----------------|-----------------------|-----------------|-------------|--------------------------------------|-------------|------------|
| 23007-602      | Объединительная плата | 5               | 3U          | CompactPCI PlusIO, CompactPCI Serial | Middle      | 4HP        |

| CatalogNumber | Product Type          | Number ofSlots | Rack Height | BackplaneType                        | System Slot | Slot Width |
|---------------|-----------------------|----------------|-------------|--------------------------------------|-------------|------------|
| 23007-601     | Объединительная плата | 8              | 3U          | CompactPCI PlusIO, CompactPCI Serial | Middle      | 4HP        |

Table 2/3

| Catalog Number | Voltage I/O | Connector Type    | Power Connector Type         | Utility Connector Type | Ширина мм | Package Quantity |
|----------------|-------------|-------------------|------------------------------|------------------------|-----------|------------------|
| 23007-602      | 5V          | HM 2.0, AirMax VS | Power Bugs for M4 Cable Lugs | MicroMatch, 8-pin      | 102.2mm   | 1                |
| 23007-601      | 5V          | HM 2.0, AirMax VS | Power Bugs for M4 Cable Lugs | MicroMatch, 8-pin      | 161.3mm   | 1                |

Table 3/3

| Catalog Number | Quick Ship |
|----------------|------------|
| 23007-602      | No         |
| 23007-601      | No         |

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**