


Система МТСА.0 для 2 одиночных полноразмерных модулей АМС, 1 HE

CATALOG NUMBER

11850-023

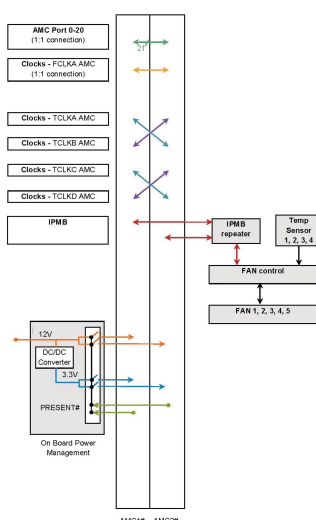

Система предназначена для 2 модулей АМС. Встроенный источник питания и выключатели питания на объединительной плате позволяют обеспечивать нагрузку по питанию для модулей АМС без необходимости в отдельном МСН.

CERTIFICATIONS



FEATURES

Маленький, компактный корпус для установки 2 одиночных полноразмерных модулей AdvancedMC с опциональным модулем-заглушкой шириной 2 HP, можно также установить 2 одиночных модуля среднего размера

Прямое соединение всех портов между обоими слотами AdvancedMC (см. топологию объединительной платы); скорость передачи данных до 10 Гбит/с на порт

Ввод переменного тока в широком диапазоне 90–264 В с обратной стороны корпуса, Блок питания 150 Вт в задней части корпуса

Включение напряжения 12 В пост. тока по сигналу наличия модуля AdvancedMC

Охлаждающая способность 150 Вт при температуре окружающей среды 55 °C, воздушный поток направлен справа налево, вентиляторы с регулировкой от температуры

Вентиляторный блок и фильтр вентилятора просты в обслуживании и легко заменяются

Штабелируемый корпус подготовлен для монтажной панели

PRODUCT ATTRIBUTES

Product Type: System

Number of Slots: 2

Type: Pico System

Backplane Type: All Ports Point to Point Connected

Data Transfer: 40 GbE; PCIe Gen3

Power per Slot: 60W

Input Voltage AC: 100 – 240V

Airflow Direction: Right to Left

Rack Height: 1U

Power Supply Type: Open Frame

Power Supply Included: Да

Rear I/O: Нет

Complies With: PICMG MTCA.0 R2.0

Глубина мм: 302mm

Package Quantity: 1

ADDITIONAL PRODUCT DETAILS

Модифицированные системы доступны по запросу.

Полностью собрано, подключено и протестировано.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause

product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE