


19-дюймовый источник питания перем. тока/пост. тока для CompactPCI, высота 6 U, ширина стойки 8 HP

CATALOG NUMBER

13100-145

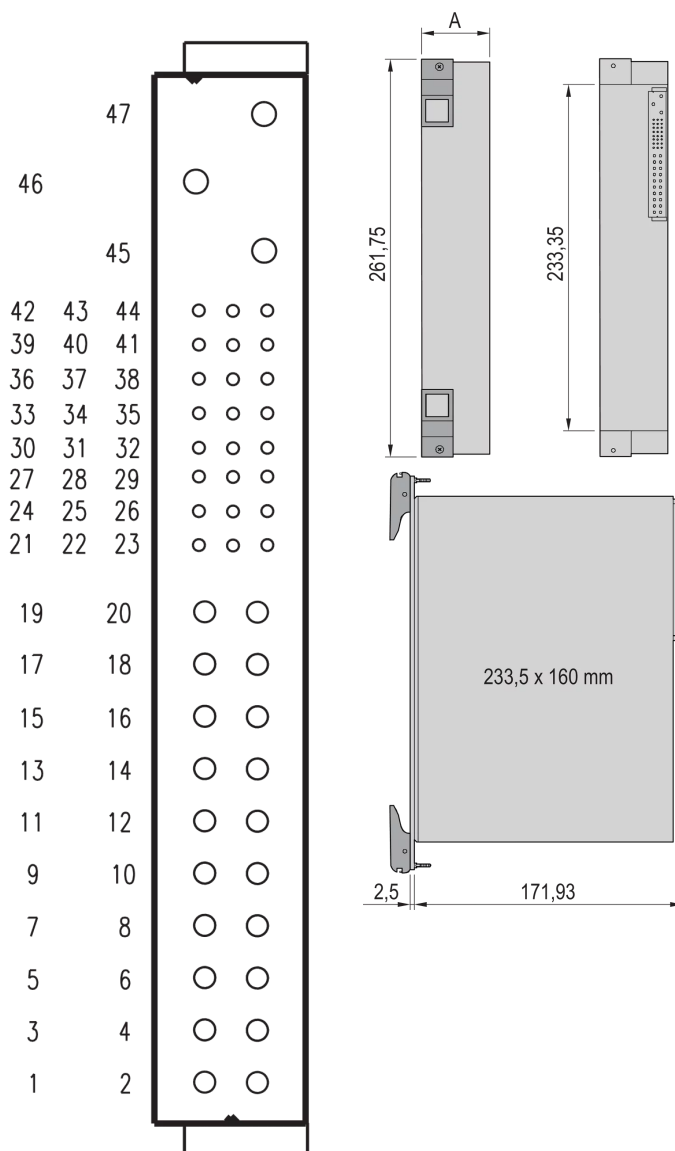

Сменные 19-дюймовые источники питания с разъемом P47 для применения в CompactPCI системах.

CERTIFICATIONS



FEATURES

Разъем P47 и сигнальные линии для CompactPCI

4 выходных напряжения

Режим работы с резервированием с токораспределяющей шиной (CSB), функция горячей замены

PRODUCT ATTRIBUTES

Product Type: Power Supply

Type: 19" Switched-Mode

Works With: CompactPCI and VME64x

Input Voltage AC: 90 – 264V

Мощность W: 500W

Number of Output Voltages: 4

Voltage 1: 5V

Current 1: 50A

Voltage 2: 3.3V

Current 2: 60A

Voltage 3: 12V

Current 3: 12A

Voltage 4: -12V

Current 4: 4A

Rack Height: 6U

Rack Width: 8HP

Глубина мм: 171.93mm

Package Quantity: 1

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE