


Монтажный кронштейн для шины 1, 2- полюсная

CATALOG NUMBER

20100-028

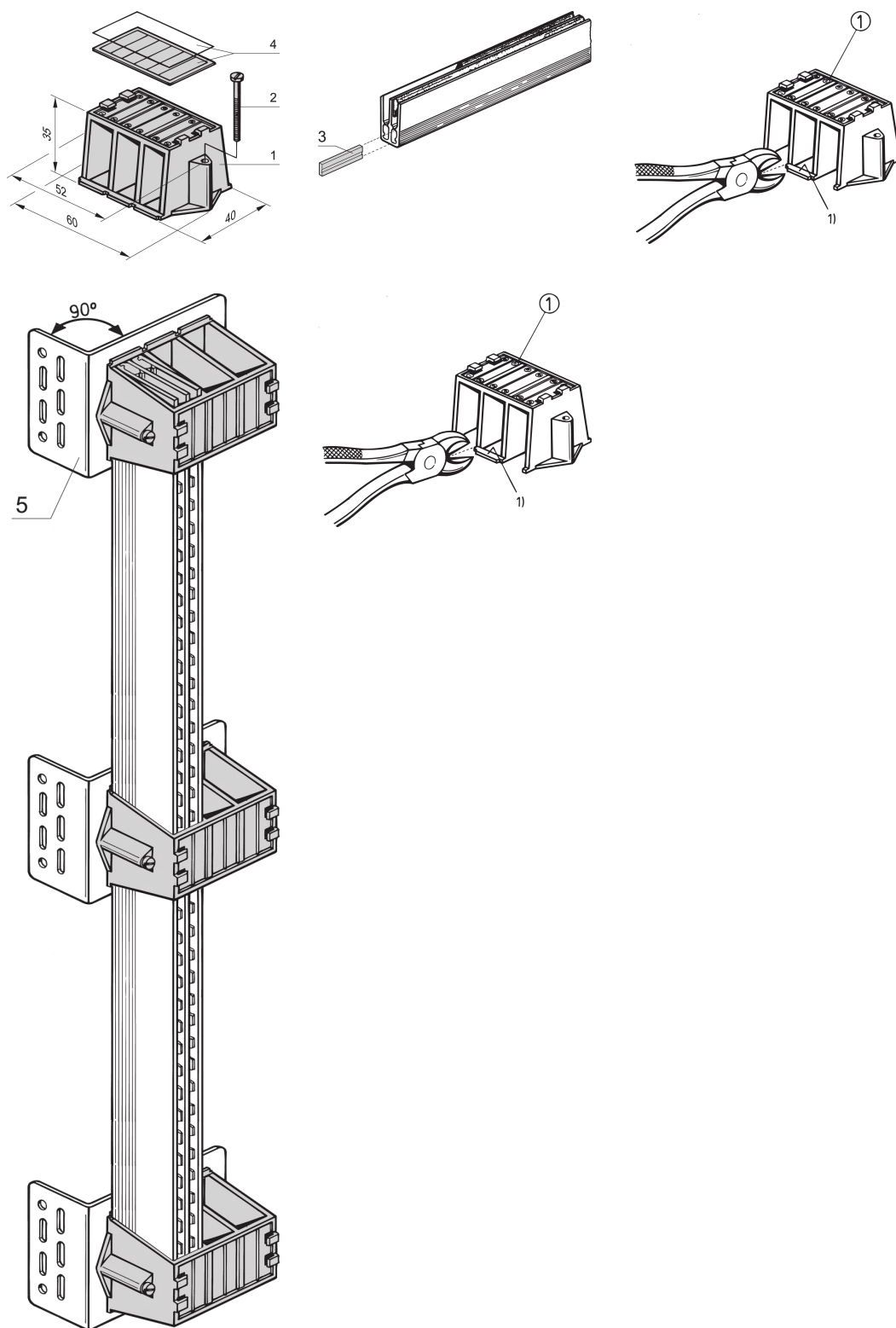

Монтажные кронштейны для шин или модулей шин представляют собой изолированные от цепи нагрузки монтажные блоки для направляющих реек заземления. Также доступны адаптеры с заданными номинальными токами, которые подают ток нагрузки на загрузочные устройства через проводные соединения.

CERTIFICATIONS



FEATURES

Монтажный кронштейн для шины, 2-полюсный

PRODUCT ATTRIBUTES

Product Type: Bracket
Type: Mounting Bracket
Works With: Токоведущая шина
Material: Polyphenylene Ether
Package Quantity: 4
Net Weight: 0.07kg

ADDITIONAL PRODUCT DETAILS

По соображениям устойчивости крепежный кронштейн должен устанавливаться с интервалом в 500 мм.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America All locations +1.763.422.2661 Chat with us: nvent.com/schroff	Europe Straubenhardt, Germany +49.7082.794.0 Betschdorf, France +33.3.88.90.64.90 Warsaw, Poland +48.22.209.98.35 Assago, Italy +39.02.932.7141 Chat with us: nvent.com/schroff	Asia Shanghai, China +86.21.2412.6943 Qingdao, China +86.532.8771.6101 Singapore +65.6768.5800 Shin-Yokohama, Japan +81.45.476.0271 Chat with us: nvent.com/schroff	Middle East & India Dubai, United Arab Emirates +971.4.378.1700 Bangalore, India +91.80.6715.2001 Istanbul, Turkey +90.216.250.7374 Chat with us: nvent.com/schroff
---	---	---	---



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE