


Микровыключатель для ручки IEL, IET с кабелем и заглушкой для сменных блоков

CATALOG NUMBER

20817-606

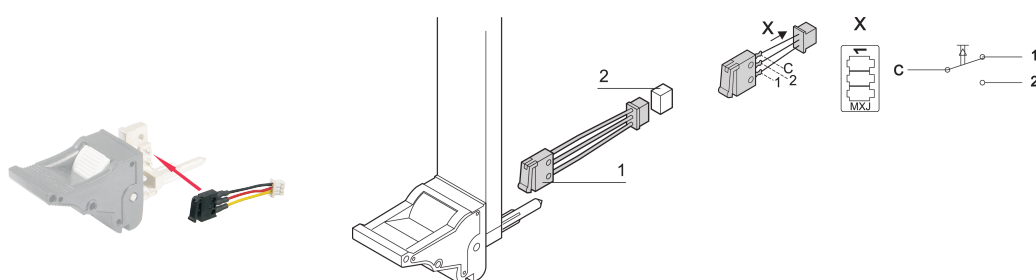

Микровыключатель для ручки IEL или IET. Микровыключатель также подходит для вариантов исполнения ручки со смещением.

CERTIFICATIONS



FEATURES

Пластмасса, поликарбонат, UL 94 V-0

Подходящие соединительные разъемы не включены в комплект поставки

Макс. коммутируемый ток 50 мА

Расчетный срок жизни $\geq 20\,000$ циклов переключения

Механический срок службы $\geq 20\,000$ циклов переключения

Корпус для разъемов Molex

Обжимной контакт Molex и фиксирующий зажим

PRODUCT ATTRIBUTES

Product Type: Выключатель

Works With: Передние панели

Material: Polycarbonate

Package Quantity: 10

ADDITIONAL PRODUCT DETAILS

Соединительный разъем не входит в комплект поставки. Соединительные разъемы от Molex, например 53261-0319, 53048-0310, 53047-0310, 53398-0319, 51047-0300.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE