


Система VME64х, высота 2 U, 4 слотов, подключаемый источник питания

CATALOG NUMBER

20836-245

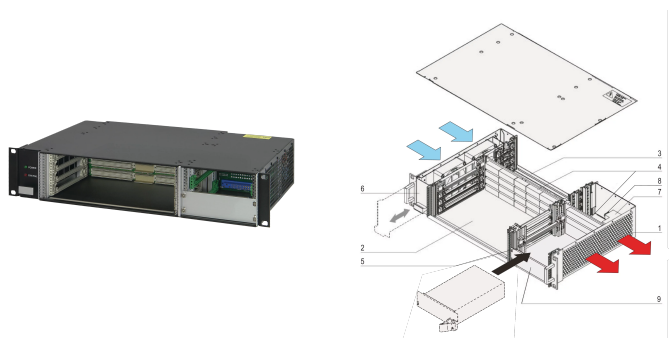

Система VME64х для 4 горизонтально установленных печатных плат VME VME64х, высота 6 U, 160 мм. Опция расположения вводов-выводов на задней панели. Питание системы осуществляется от бескорпусного источника питания. Вентиляторный блок с возможностью горячей замены с 4 вентиляторами обеспечивает превосходный уровень охлаждения.

CERTIFICATIONS



FEATURES

Система в соответствии с IEC 60297-3-101, 102, 103; IEEE 1101.1, 1101.10/11; объединительная плата соответствует требованиям VITA 1.1-1997

Блоки питания, 19" совместимый, 250 Вт; дополнительно возможна установка второго блока питания

Силовая объединительная плата согласно PICMG 2.11 (P 47), возможность монтажа двух 19" совместимых блоков питания,, 250 Вт (3 U, 8 HP)

Отвод тепла: вентиляторный блок с 2 вентиляторами, охлаждение справа налево; мониторинг вентиляторов и отображение напряжения

Система для горизонтального крепления печатных плат с учетом форматов платы; Спереди: 6 U, глубина 160 мм; Сзади:, задняя панель ввода-вывода: 6 U, глубина 80 мм

PRODUCT ATTRIBUTES

Product Type: System

Number of Slots: 4

Type: 19" Rack Mount

Backplane Type: 6 U VME64 Extension

Data Transfer: VME64; VME2eSST

Power per Slot: 30W

Input Voltage AC: 100 – 240V

Airflow Direction: Left to Right

Rack Height: 2U

Power Supply Type: (2) Pluggable PSU

Power Supply Included: Нет

Rear I/O: Да

Complies With: ANSI/VITA 1.1-1997

Глубина мм: 277.5mm

Высота мм: 88.1mm

Ширина мм: 449mm

Package Quantity: 1

ADDITIONAL PRODUCT DETAILS

Модифицированные системы доступны по запросу.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE