


Система VMEbus, высота 3 U, 5 слотов, бескорпусный источник питания

CATALOG NUMBER

20836-310

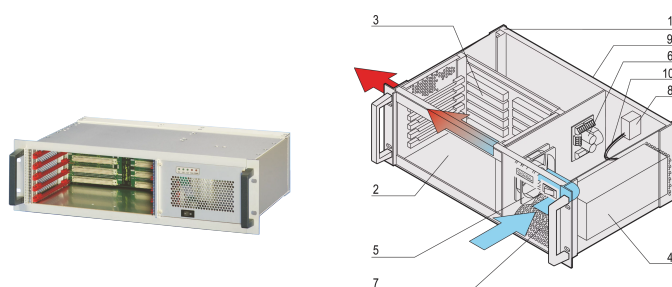

Система VME для 5 горизонтально установленных печатных плат VME 6 U, 160 мм. Питание системы осуществляется от бескорпусного источника питания. Модуль управления вентилятором контролирует работу вентиляторов, следит за температурой и напряжением.

CERTIFICATIONS



FEATURES

Система в соответствии с IEC60297-3-101, -102, -103 IEEE 1101.1, 1101.10/11; объединительная плата в соответствии с VITA 1-1994

Источник питания с открытым корпусом, 250 Вт

Отвод тепла осуществляется 1 вентилятором, воздушный поток направляется спереди налево; управляется модулем управления вентилятором (FCM) в зависимости от температуры

Система для установки печатных плат в горизонтальном положении с учетом формата платы, 6 U, глубина 160 мм

Модуль индикации рабочего напряжения (пост. ток), аварийные сигналы от вентиляторов и датчиков температуры

Backplane VME 5 slot, 6 U, J1/J2 monolithic in accordance with VITA 1-1994

PRODUCT ATTRIBUTES

Product Type: System

Number of Slots: 5

Type: 19" Rack Mount

Backplane Type: 6 U VME64

Data Transfer: VME64; VME2eSST

Power per Slot: 30W

Input Voltage AC: 100 – 240V

Airflow Direction: Front to Left

Rack Height: 3U

Power Supply Type: Open Frame

Power Supply Included: Да

Rear I/O: Нет

Complies With: ANSI/VITA 1.1-1994

Глубина мм: 277.5mm

Высота мм: 132.55mm

Ширина мм: 449mm

Мощность W: 200W

Package Quantity: 1

ADDITIONAL PRODUCT DETAILS

Модифицированные системы доступны по запросу.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE