


# Система VMEbus, высота 7 U, 12 слотов, для переходных модулей, бескорпусной ИСТОЧНИК ПИТАНИЯ

## CATALOG NUMBER

**20836-716**

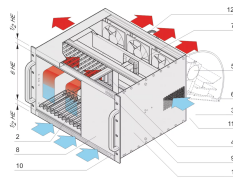

Система VME для 12 печатных плат VME 6 U, 160 мм. Питание системы осуществляется от бескорпусного источника питания. Модуль управления вентилятором контролирует работу вентиляторов, следит за температурой и напряжением.

## CERTIFICATIONS



## FEATURES

Система в соответствии с IEC60297-3-101, -102, -103 IEEE 1101.1, 1101.10/11; объединительная плата соответствует требованиям VITA 1.1-1994

Блоки питания, бескорпусного типа, 444 Вт (400 Вт при < 180 В перем.тока)

Отвод тепла с помощью 3 вентиляторов (задняя панель), воздушный поток направляется спереди назад; управление температурой с помощью модуля управления вентилятором (FCM)

Модуль индикации рабочего напряжения (пост. ток), аварийные сигналы от вентиляторов и датчиков температуры

Система для вертикального крепления печатных плат с учетом форматов платы, Передняя панель: 6 U, глубина 160 мм, Задняя панель: 6 U, 12 HP, глубина 80 мм; для интерфейсных модулей

Backplane VME 12 slot, 6 U, J1/J2 monolithic in accordance with VITA 1-1994

## PRODUCT ATTRIBUTES

---

Product Type: System

Number of Slots: 12

Type: 19" Rack Mount

Backplane Type: 6 U VME64

Data Transfer: VME64; VME2eSST

Power per Slot: 30W

Input Voltage AC: 100 – 240V

Airflow Direction: Front to Rear

Rack Height: 7U

Power Supply Type: Open Frame

Power Supply Included: Да

Rear I/O: Да

Complies With: ANSI/VITA 1.1-1994

Глубина мм: 355mm

Высота мм: 310.35mm

Ширина мм: 449mm

Мощность W: 450W

Package Quantity: 1

## ADDITIONAL PRODUCT DETAILS

---

Модифицированные системы доступны по запросу.

## WARNING

---

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations

+1.763.422.2661

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**