


Система VME64x, высота 8 U, 21 слотов, открытая рама источника питания

CATALOG NUMBER

20836-820

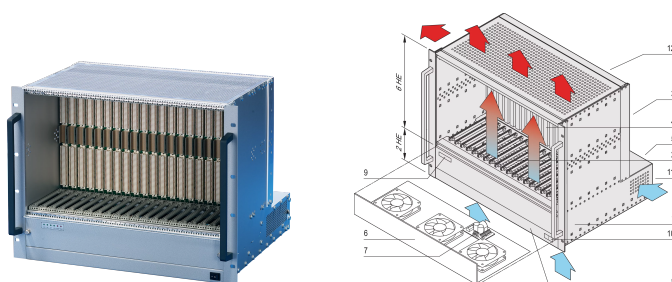

Система VME64 для 21 печатных плат VME64x, высота 6 U, 160 мм. Опция расположения вводов-выводов на задней панели. Питание системы осуществляется от бескорпусного источника питания. Модуль управления вентилятором контролирует работу вентиляторов, следит за температурой и напряжением.

CERTIFICATIONS



FEATURES

Система в соответствии с IEC 60297-3-101, 102, 103; IEEE 1101.1, 1101.10/11; объединительная плата соответствует требованиям VITA 1.1-1997

Блоки питания, бескорпусного типа, 642 Вт (600 Вт при < 180 В перем.тока)

Backplane VME64x 21 slot, 6 U, J1/J2, монолитная, с разъемом P0, соответствует требованиям VITA 1-1994 и 1.1-1997

Отвод тепла 3 вентиляторами, воздушный поток направляется снизу вверх; управление температурой с помощью модуля управления вентилятором (FCM)

Система для вертикального крепления печатных плат с учетом формата платы, 6 U, глубина 160 мм, опция расположения вводов-выводов на задней панели

Модуль индикации рабочего напряжения (пост. ток), аварийные сигналы от вентиляторов и датчиков температуры

PRODUCT ATTRIBUTES

Product Type: System

Number of Slots: 21

Type: 19" Rack Mount

Backplane Type: 6 U VME64 Extension

Data Transfer: VME64; VME2eSST

Power per Slot: 30W

Input Voltage AC: 100 – 240V

Airflow Direction: Bottom to Top

Rack Height: 8U

Power Supply Type: Open Frame

Power Supply Included: Да

Rear I/O: Да

Complies With: ANSI/VITA 1.1-1997

Глубина мм: 412mm

Высота мм: 354.8mm

Ширина мм: 449mm

Мощность W: 600W

Package Quantity: 1

ADDITIONAL PRODUCT DETAILS

Модифицированные системы доступны по запросу.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE