


Вентилятор верхней крышки Varistar, высота 38 мм, 162 м³/ч

CATALOG NUMBER

23130-165

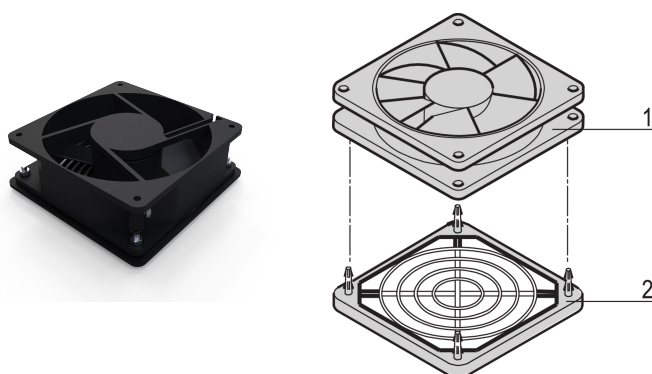

Крышки с вентиляторами являются компактными блоками активного охлаждения, которые не занимают места в шкафу. Вентилятор Varistar для верхней крышки поставляется с высокими техническими характеристиками.

CERTIFICATIONS



FEATURES

Вентилятор верхней крышки Varistar, высота 38 мм, 162 м³/ч

PRODUCT ATTRIBUTES

Product Type: Fan

Product Family: Varistar

Works With: Varistar CP

Voltage AC: 230V

Глубина мм: 119mm

Частота: 50/60 Hz

Airflow @ 50 Hz: 162m³/h

Airflow @ 60 Hz: 192m³/h

Noise Level @ 50 Hz: 37dB(A)

Noise Level @ 60 Hz: 41dB(A)

Power @ 50 Hz: 15W

Power @ 60 Hz: 14W

Max Static Pressure @ 50 Hz: 73Pa

Max Static Pressure @ 60 Hz: 88Pa

Ambient Temperature: 70°C

Высота мм: 38mm

Ширина мм: 119mm

Finish: Powder Coated

Material: Сталь

Package Quantity: 1

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE