
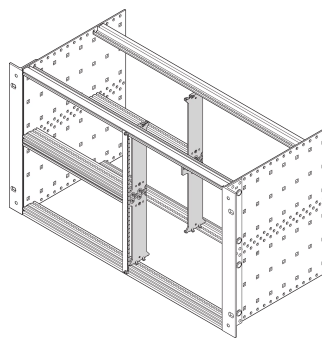


Разделительный профиль 6 U для комбинированного монтажа, повышенной прочности

CATALOG NUMBER

24566-400

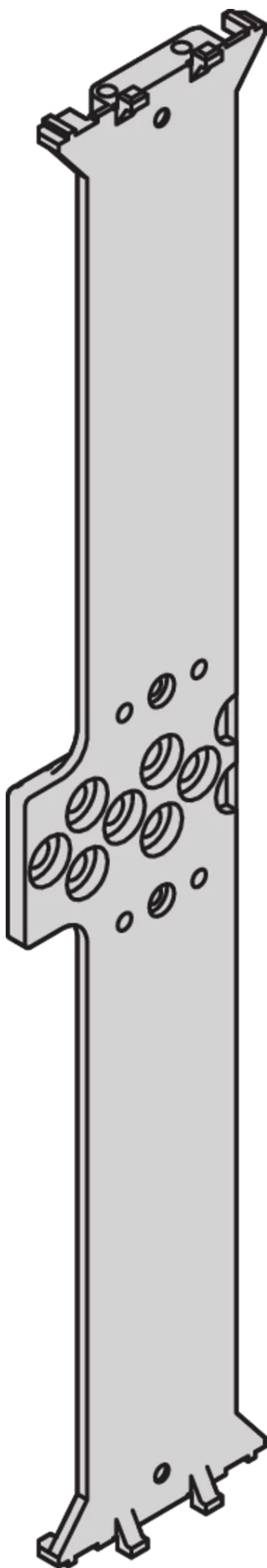

Опора крепится винтами в отверстия сетки горизонтальных рельсов и позволяет разделить блочный каркас 6 U на части 2 x 3 U.

CERTIFICATIONS



FEATURES

Средний горизонтальный рельс «усиленный» или «облегченный»), заказывается отдельно

Разделительная панель для комбинированного монтажа в одном блочном каркасе (установка 6 U и установка 2 x 3 U)

Передняя сторона должна быть закрыта передней панелью 2 HP

PRODUCT ATTRIBUTES

Product Type: Mounting Kit

Product Family: EuropacPRO

Type: Combined, Rugged

Works With: Блочный каркас

Material: Zinc Alloy

Rack Height: 6U

Package Quantity: 2

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE